


Technical data

HK4016F

Drawn cup needle roller bearings, opened end

Needle roller bearing, drawn cup, open end

VISUAL (S)

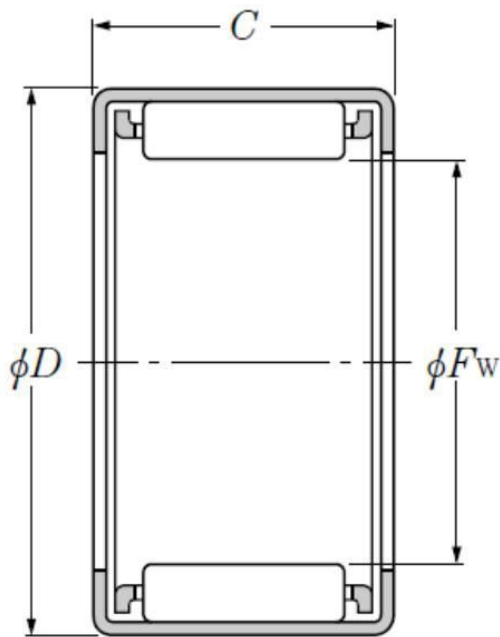

PRODUCT DEFINITION

Brand	NTN
Fw - Under rollers diameter	40 mm
D - External diameter	47 mm
C - Width of bearing, drawn cup or outer ring	16 mm
Lubrication hole on outer ring	Non/No
Inner ring reference	IR35X40X17
Mass	0,041 kg

PRODUCT PERFORMANCE



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

HK4016F

Drawn cup needle roller bearings, opened end

PRODUCT PERFORMANCE

Cr - Dynamic load rating	20,3 kN
C0r - Static load rating	38,5 kN
N lim - Grease lubrication limit speed	4000 tr/min
N lim - Oil lubrication limit speed	6000 tr/min
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	120 °C

ESHOPDONOTDISPLAY

Tracepart	Oui/Yes
Reference	HK4016F
Image	NRBHK_1.jpg, NRBHK_3.jpg
Rolling element material	Acier 100Cr6



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15