


Mounting plate 3VA13 (400 A), 3VA14 (630 A), 3VA23 (400 A), 3VA24 (630 A), 3-pole, fixed-mounted, RCD: without, H: 450 mm W: 800 mm

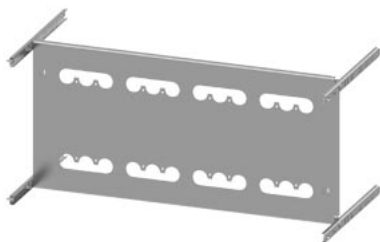

| Model                      |             |
|----------------------------|-------------|
| product brand name         | SIVACON S4  |
| General technical data     |             |
| surface processing         | Galvanized  |
| product feature perforated | Yes         |
| Mechanical Design          |             |
| height                     | 350 mm      |
| width                      | 800 mm      |
| depth                      | 400 mm      |
| net weight                 | 4.76 kg     |
| material                   | sheet-steel |
| Approvals Certificates     |             |
| General Product Approval   | other       |

[Miscellaneous](#)



[Confirmation](#)

### Environment

[Environmental Con-  
firmations](#)

[Environmental Con-  
firmations](#)

### Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8PQ6000-8BA57>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8PQ6000-8BA57>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)

[http://www.automation.siemens.com/bilddb/cax\\_en.aspx?mlfb=8PQ6000-8BA57](http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8PQ6000-8BA57)

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>



