

64333 B 40-15

Halogen lamps with reflector, current-controlled, 30...40 W



Product benefits

- Reduced operation and maintenance costs due to long life time
- Instant and constant light output over the lamp life
- Flicker-free operation
- Mercury-free

Product features

- Dimmable
- Available with connector combinations A, B, C/Z on request
- Infrared radiation output that provides light in the worst of conditions

Technical data

Electrical data

Nominal wattage	40 W
Nominal current	6.60 A


Light technical data

Axial luminous intensity	12700 cd
Luminous intensity	10000 cd ¹⁾

¹⁾ Minimum

Dimensions & weight

Diameter	35.3 mm
Length with base excl. base pins/connection	37.00 mm
Length	35.0 mm

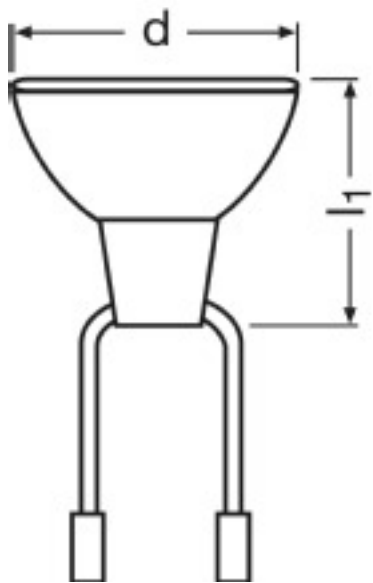

Product line drawing

Lifespan

Lifespan	1500 h
----------	--------

Capabilities

Burning position	h45
------------------	-----

Country specific categorizations

Order reference	64333
-----------------	-------

Safety advice

To prevent personal injury or damage to property, halogen lamps may only be operated in suitable luminaires designed with suitable mechanisms (protective shields, grids, etc.) to ensure that in the event of a lamp bursting no parts/shards can escape and that during operation no ultraviolet radiation can escape. There must also be a warning sign to indicate that the lamps give off high levels of heat. Detailed information is available on request.



Burning position

Logistical Data

Product code	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Gross weight	Volume
4008321104731	Folding carton box 1	34 mm x 34 mm x 50 mm	19.00 g	0.06 dm ³
4008321104748	Shipping carton box 20	83 mm x 130 mm x 191 mm	448.00 g	2.06 dm ³

References / Links

For more information on airfield lamps see the brochure:

"The reliable guiding stars - Effective solutions for airfield lighting: Tungsten halogen lamps and LED light sources".

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.