
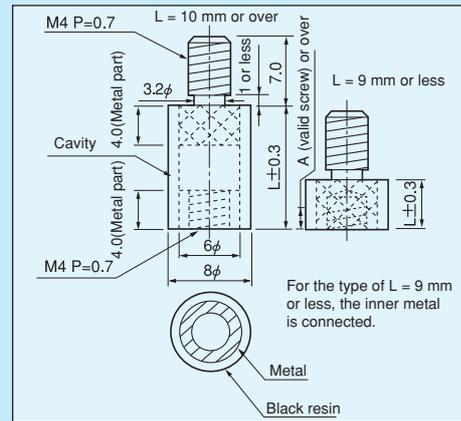


Spacer of metal resin type for printed board [4AP, 4AQ series] (100pcs/pack)

- The strength of this spacer is increased by filling metal in the resin.
- For the type of 10 mm or over, the upper part and the lower part are electrically insulated.
- For the type of 9 mm or less, they are electrically connected.
- Material Resin part: PBT black (UL94V-0)
Metal part: Brass
- Finish: Nickel plating
- Operating temperature range: -40 to +125°C

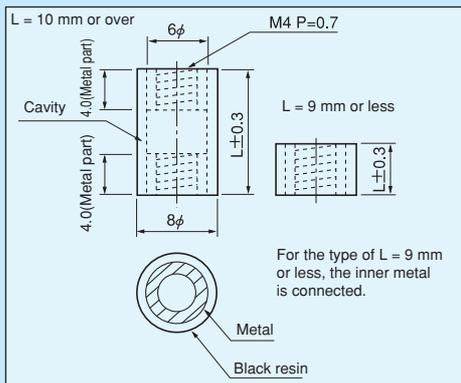

4AP type (for M4)

Part number	L (mm)
4AP- 4	4
4AP- 5	5
4AP- 6	6
4AP- 7	7
4AP- 8	8
4AP- 9	9
4AP-10	10
4AP-11	11
4AP-12	12
4AP-13	13
4AP-14	14
4AP-15	15
4AP-16	16
4AP-17	17
4AP-18	18
4AP-19	19
4AP-20	20
4AP-25	25
4AP-30	30
4AP-35	35
4AP-40	40
4AP-45	45
4AP-50	50

4AQ type (for M4)

Part number	L (mm)	A (or over)
4AQ- 6	6	3
4AQ- 7	7	4
4AQ- 8	8	5
4AQ- 9	9	5
4AQ-10	10	
4AQ-11	11	
4AQ-12	12	
4AQ-13	13	
4AQ-14	14	
4AQ-15	15	
4AQ-16	16	
4AQ-17	17	
4AQ-18	18	
4AQ-19	19	
4AQ-20	20	
4AQ-25	25	
4AQ-30	30	
4AQ-35	35	
4AQ-40	40	
4AQ-45	45	
4AQ-50	50	