

# ALPHA

## 3370BOG100P62 TFR

EAN 4031582397833

Swivel castor, housing made of pressed steel, bright zinc plated, blue passivated, double ball bearing swivel head, wheel axle with nut, plate fitting. Wheel made of heat resisting synthetic material, self-lubricating bushing



BETTER MOBILITY. BETTER LIFE.




Picture may differ from original product

### Technical Data

Wheel diameter	100 mm
Wheel width	35 mm
Size of Plate	105 x 85 mm
Plate hole centres	80/77 x 60 mm
Plate hole	9 mm
Offset	41 mm
Swivel Interference	182 mm
Overall height	128 mm
Temperature	- 40 / + 280 °C
Standard	EN_12532
Weight	0.67 kg
Swivel Radius	91 mm
Hardness of tread	Shore D 85
Load capacity	125 kg
Load capacity (static)	250 kg

### Structure & Mounting

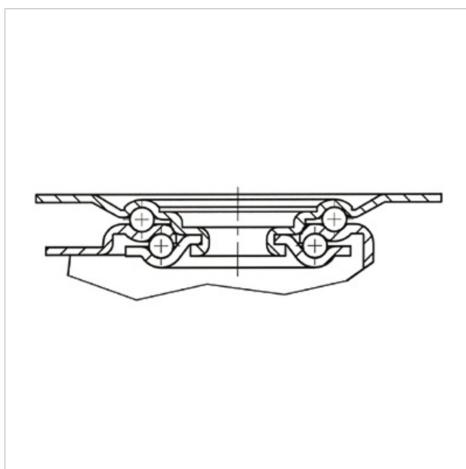

### Advantages at a glance

Roll performance	● ● ● ● ○
Movement noise	● ● ● ○ ○
Attrition	● ● ● ● ●
Corrosion resistance	● ● ● ● ●

# ALPHA

3370BOG100P62 TFR

EAN 4031582397833



BETTER MOBILITY. BETTER LIFE.

## Structure & Mounting

