



Brand of NTN corporation


Technical data

BBER20LAUU

Flange type ball bushings



VISUAL (S)

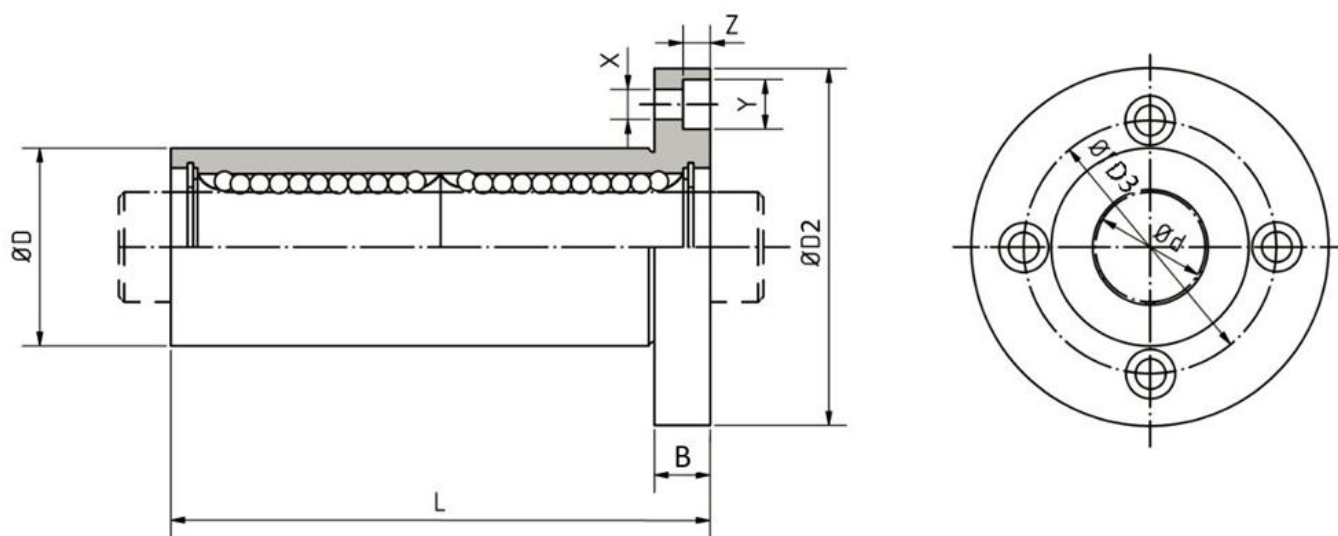

PRODUCT DEFINITION

Brand	SNR
Design type	BBER
Ball bushings category	Flange type ball bushings
Standard	ISO dimension
Number of seals	2
Material outer cylinder or steel segments	100Cr6
Material Cage	RSt34-2
Initial greasing	Non/No
d - Internal diameter	20 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

d - Internal diameter tolerance	0,011/-0,001
D - External diameter	32 mm
D - External diameter tolerance	0/-0,019
L - Length	80 mm
L - Length tolerance	0,3/-0,3
B - Flange width	8 mm
D2 - Diameter	54 mm
D3 - Diameter	43 mm
X	5,5 mm
Y	9 mm
Z	5,1 mm
Maximum eccentricity	0,017 mm
Number of ball rows	5
Mass	0,26 kg

PRODUCT PERFORMANCE

Cmin	1,44 kN
Cmax	2,107 kN
C0min	2,74 kN
C0max	4,009 kN
Permissible static Moment My	25 N/m
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	110 °C

ESHOPDONOTDISPLAY



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

BBER20LAUU

Flange type ball bushings

ESHOPDONOTDISPLAY

Reference	BBER20LAUU
Image	BBER-L_1.JPG, BBER-L_3.JPG
Send to Eshop	Yes
Send to Paper Catalog	Yes
Tracepart	Oui/Yes



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15