


E70599



AS-Interface flat cable insulation displacement connector

FC Splitter AS-i 5 m UL

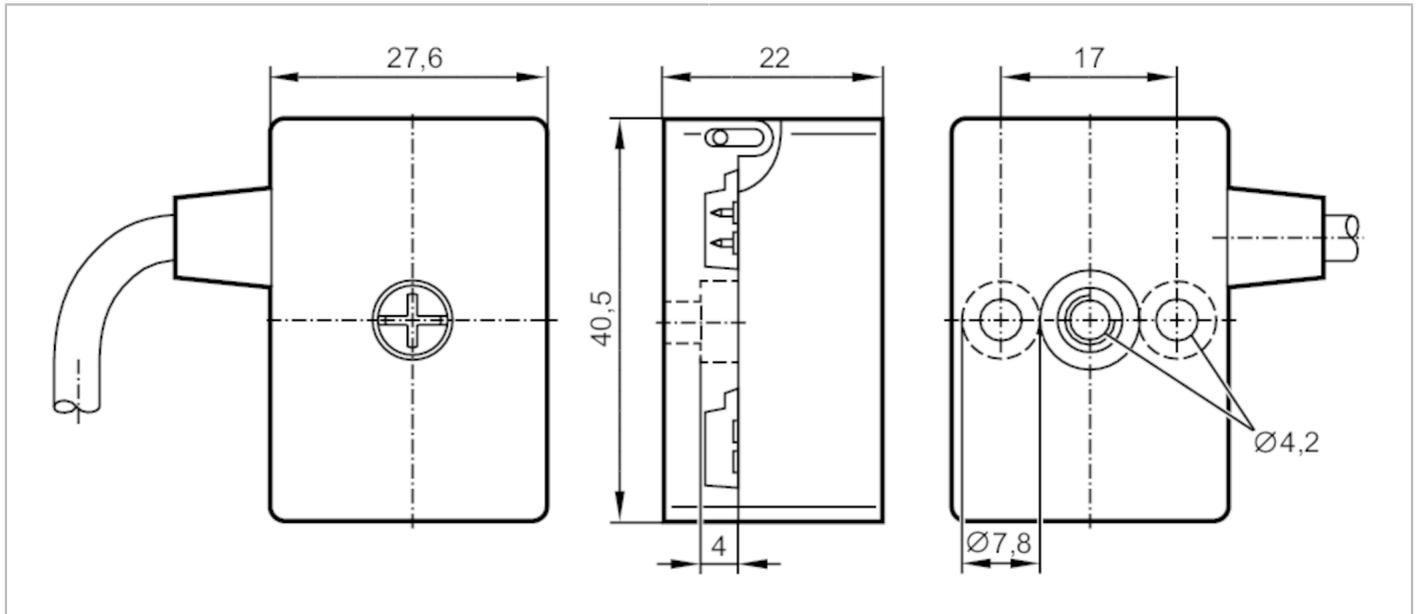

Electrical data	
Protection class	III
Max. current load per module/slot [A]	4
Outputs	
Electrical design	AS-i
Operating conditions	
Ambient temperature [°C]	-25...75
Protection	IP 67
Mechanical data	
Weight [g]	182.8
Materials	housing: PBT / PC; screw: stainless steel (303/1.4305)
Tightening torque [Nm]	< 1.65
Accessories	
Accessories (optional)	flat cable end seal, E70413 heat-shrink cap, E70113
Remarks	
Remarks	The flat cable should not end in the splitter. Use a flat cable seal or heat-shrink cap for sealing.
Pack quantity	1 pcs.

E70599




AS-Interface flat cable insulation displacement connector

FC Splitter AS-i 5 m UL

Electrical connection

Cable: 5 m, Ø 4.3 mm; 2 x 0.5 mm²

Connection

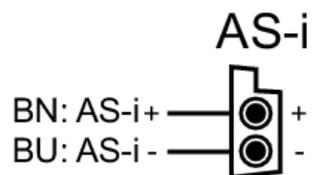

brown	AS-i +
blue	AS-i -