


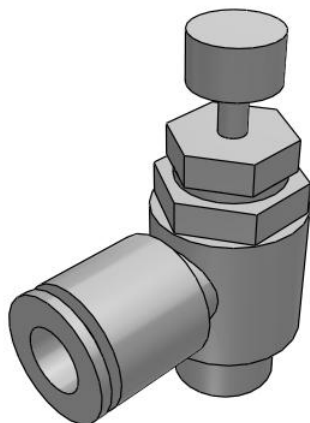


## Elbow - AS\*2\*1F AS2201F-01-06S-X214

### Datasheet

### General series information

 - Port Size: M3, M5, 10-32 UNF, 1/8, 1/4, 3/8, 1/2
- Applicable Tubing O.D.: Ø 2 to Ø 12 mm and Ø 1/8" to Ø 1/2"
- Operating Pressure Range: 0.1 to 1 MPa.




Flow control valve, adjustable, with reverse free flow


### Standard specifications

|                             |                                         |
|-----------------------------|-----------------------------------------|
| Size                        | 22 (1/8, 1/4 Basis - elbow)             |
| Control Method              | 0 (Meter-out)                           |
| Port Size and Tube Size     | 01-06 (Port Size R1/8 - Tube Size ø6)   |
| Option                      | S (Sealant)                             |
| Fixed Orifice               | None                                    |
| Made to Order               | X214 (Restrictor [Without Check Valve]) |
| Lock Nut                    | Standard (Hexagon)                      |
| Pressure medium             | Air                                     |
| Maximum operating pressure  | 1 MPa                                   |
| Minimum operating pressure  | 0.1 MPa                                 |
| Proof pressure              | 1.5 MPa                                 |
| Maximum ambient temperature | 60 °C                                   |
| Minimum ambient temperature | -5 °C                                   |
| Applicable tubing material  | Nylon, Soft nylon, Polyurethane         |
| Weight                      | 0.154 Kg                                |

Dimensions

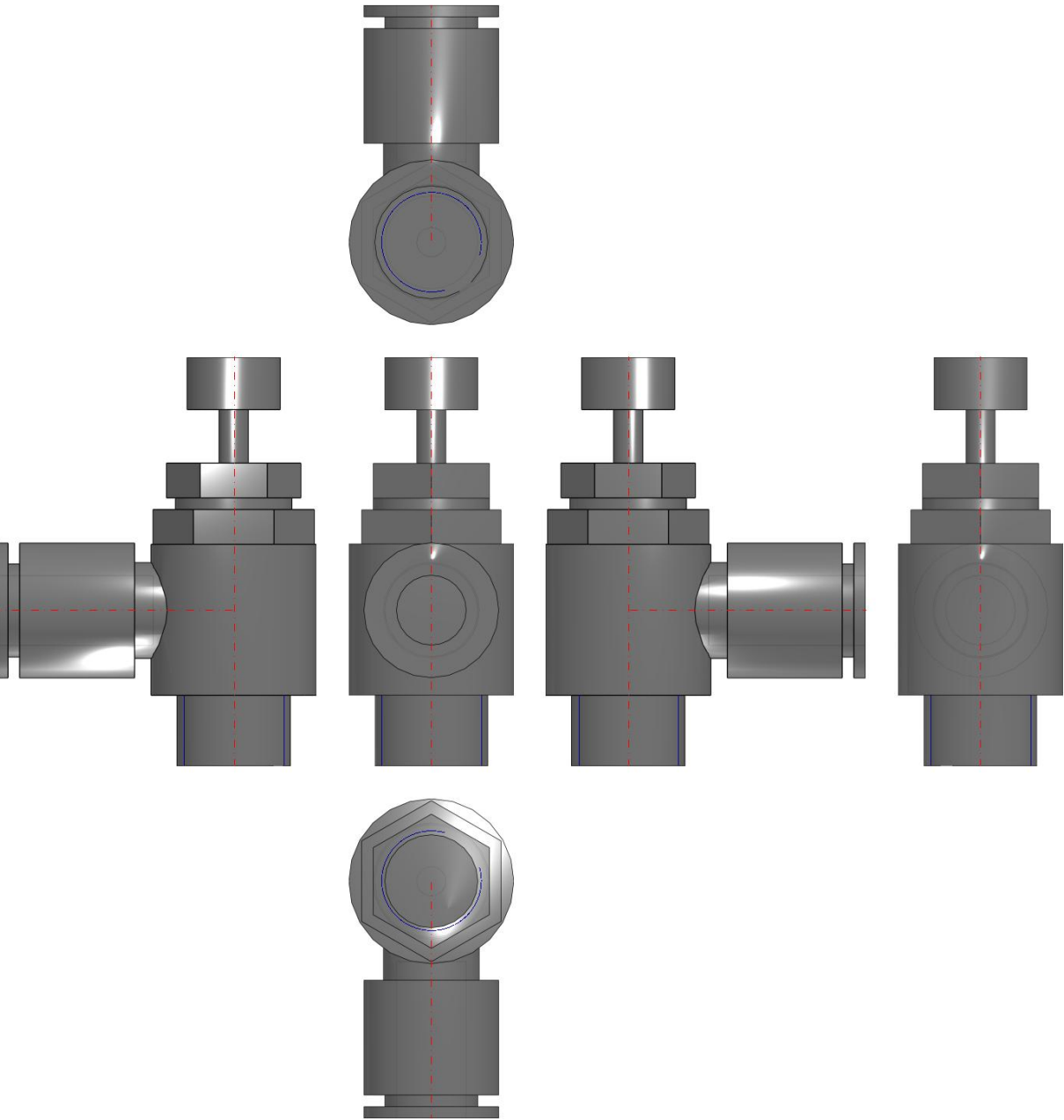

## Constructions

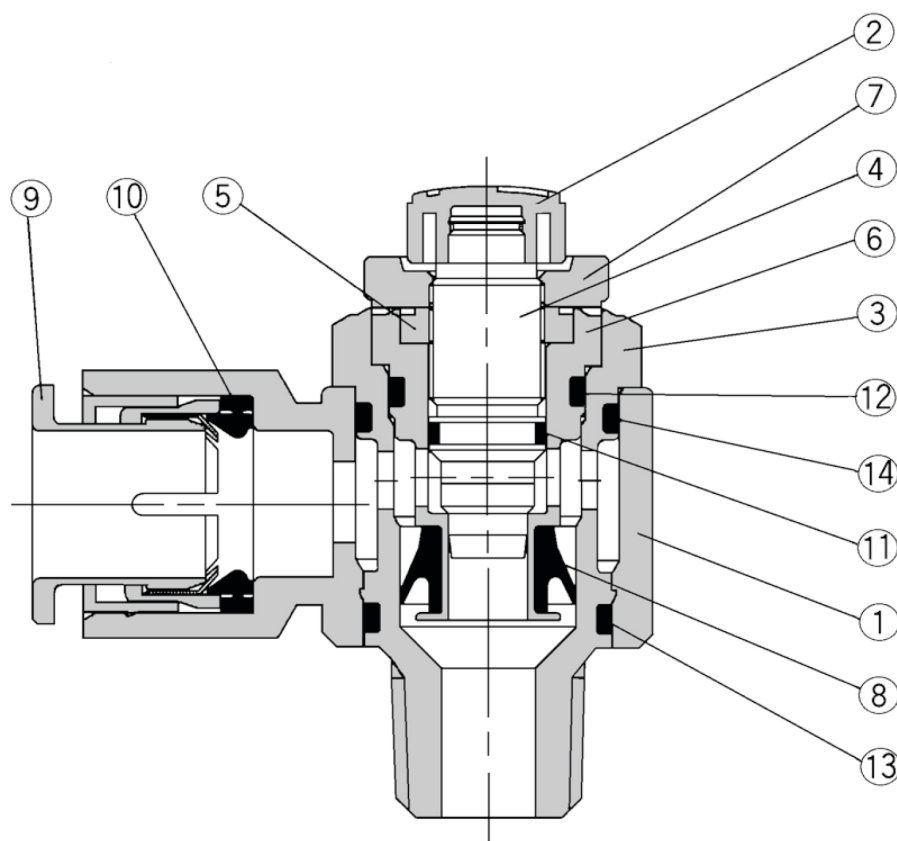

## Component Parts

| No. | Description  |                      |
|-----|--------------|----------------------|
| ①   | Body A       | PBT                  |
| ②   | Handle       | PBT <sup>(1)</sup>   |
| ③   | Body B       | Brass <sup>(2)</sup> |
| ④   | Needle       | Brass                |
| ⑤   | Needle guide | Brass                |
| ⑥   | Seat ring    | Brass                |
| ⑦   | Lock nut     | Steel                |
| ⑧   | U-packing    | HNBR                 |
| ⑨   | Cassette     | POM, Stainless steel |
| ⑩   | Packing      | NBR                  |
| ⑪   | O ring       | NBR                  |
| ⑫   | O ring       | NBR                  |
| ⑬   | O ring       | NBR                  |
| ⑭   | O ring       | NBR                  |

Note 1) AS12□1F-M3-02 and AS12□1F-M5-02 are made of electroless nickel plated brass.

Note 2) AS12□1F-M3: Stainless

Note 3) AS22□1F, AS32□1F-02: Electroless nickel plated

Note 4) Meter-in type: Black zinc chromated

## Additional information

|                   |                                         |
|-------------------|-----------------------------------------|
| Catalogue         | <a href="#">AS_2-3_1F-A_EU.pdf</a>      |
| Operation manuals | <a href="#">OM_AS-F_OMG0107EN-A.pdf</a> |