



Edge protection grommets

Edge protection grommets are used wherever cable and wires are routed through outlets and apertures. HellermannTyton grommets offer excellent mechanical protection.


Features and Benefits

- Protects cables from sharp edges
- Provides additional strain relief
- Flexible and easy to apply
- High resistance to chemicals and environmental influences




Edge protection grommets.


MATERIAL	Polyvinylchloride (PVC)	Polyvinylchloride, flame retardant (PVC-FR)
Operating Temperature	-30 °C to +60 °C	
Shore Hardness A	70±5	56±5
Flammability	UL94 HB	UL94 V0

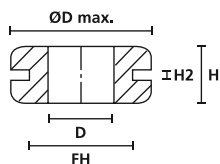


HV1101

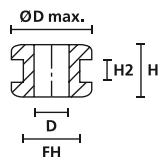


HV1201 to HV1218

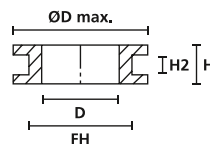


HV1301 to HV1305

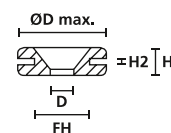


HV1401

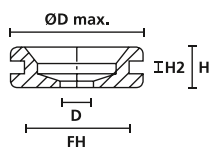


HV1402

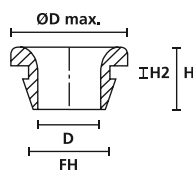


HV1502 to OP1503

 


HV1606 to HV1608

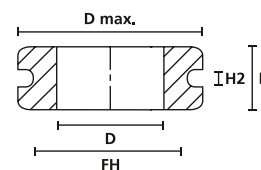

HV1606 to HV1608

 

HV1606 to HV1608

 

Edge protection grommets

TYPE	Drawing	Bundle Ø max.	Hole Ø (FH)	Ø D	Height (H)	Height (H2)	Material	Colour	Article-No.
HV1101		25.5	19.0	12.0	10.0	1.6	PVC-FR	Black (BK)	633-01010
HV1212		9.0	6.0	4.0	7.0	1.0	PVC-FR	Black (BK)	633-02120
HV1201		9.5	6.4	4.0	5.6	1.6	PVC-FR	Black (BK)	633-02010
HV1201B		9.5	6.4	4.0	6.5	2.5	PVC-FR	Black (BK)	633-02020
HV1215		10.0	8.0	6.0	5.0	1.0	PVC-FR	Black (BK)	633-02150
HV1209		11.0	9.0	4.0	5.5	1.5	PVC-FR	Black (BK)	633-02090
HV1208		14.0	9.5	8.0	8.0	1.5	PVC-FR	Black (BK)	633-02080
HV1207		14.0	10.0	6.0	6.4	1.5	PVC-FR	Black (BK)	633-02070
HV1218		14.0	10.0	6.0	9.0	4.0	PVC-FR	Black (BK)	633-02180
HV1216		14.5	8.0	5.0	6.5	1.5	PVC-FR	Black (BK)	633-02160
HV1210		15.0	9.0	6.0	10.5	2.0	PVC-FR	Black (BK)	633-02100
HV1203		17.5	12.0	10.0	6.8	2.0	PVC-FR	Black (BK)	633-02030
HV1204		17.5	12.0	10.0	8.8	4.0	PVC-FR	Black (BK)	633-02040
HV1206		17.5	12.0	10.0	10.8	6.0	PVC-FR	Black (BK)	633-02060
HV1205		17.5	13.5	10.0	8.7	4.0	PVC-FR	Black (BK)	633-02050
HV1303		15.9	11.0	8.0	6.4	1.6	PVC-FR	Black (BK)	633-03030
HV1301		15.9	11.0	8.0	7.0	1.0	PVC-FR	Black (BK)	633-03010
HV1302		15.9	11.0	8.0	9.0	3.0	PVC-FR	Black (BK)	633-03020
HV1304		15.9	11.0	8.0	10.8	6.0	PVC-FR	Black (BK)	633-03040
HV1305		24.0	18.0	14.0	7.0	3.0	PVC-FR	Black (BK)	633-03050
		24.0	18.0	14.0	7.0	3.0	PVC-FR	White (WH)	633-03059
HV1401		15.9	9.5	5.0	4.8	0.8	PVC-FR	Black (BK)	633-04010
HV1402		23.0	18.5	6.0	7.0	2.0	PVC-FR	Black (BK)	633-04020
HV1502		11.5	8.0	6.5	8.0	1.5	PVC	Black (BK)	633-05020
HV1606		31.0	25.0	17.0	11.0	3.0	PVC-FR	Grey (GY)	633-06068
HV1607		43.0	37.0	29.0	11.0	3.0	PVC-FR	Grey (GY)	633-06078
HV1608		58.0	52.0	44.0	11.0	3.0	PVC-FR	Grey (GY)	633-06088

All dimensions in mm. Subject to technical changes.