



1797435 ELECTRO MECHANICAL TRANSDUCER

SOUNDERS & BUZZERS

Specifications


	1797435
Rated voltage (Vp-p square wave)	12Vp-p
Operating voltage	6~15Vp-p
Rated current at rated voltage	≤40mA
Sound output at 2400Hz, 12V at10cm	≥85dB
Resonant frequency at rated voltage	2400Hz
Coil resistance	140±14Ω
Operating temperature	-30~+70°C
Storage temperature	-40~+85°C
Weight	2g

Requires additional electronic circuitry to operate as a sounder

Features

- ROHS compliant
- Sealed base
- Wave solderable and washable
- Housing material: Noryl

All data at 25°C unless otherwise specified

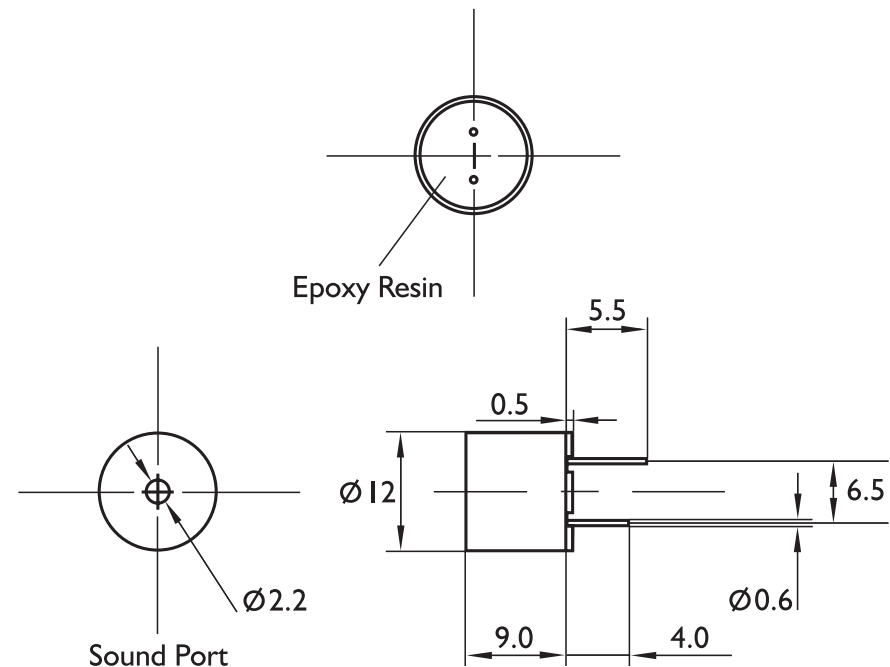

Dimensions Unit: mm Tolerance: ±0.5mm