

Blanking Plug

Features


- RND can help you complete your job by ensure all open orifice's on enclosures, junction boxes are completely sealed
- Easy to use and tighten they are the idea solution when no cable gland is required
- They will provide a clean finish at a great cost



Specification

Material	Polyamide (PA)
Glass-Fibre Reinforced	No
Shock Resistant	No
Explosion-Tested Version	No
For Ex-Zone Gas	None
For Ex-Zone Dust	None
Surface Protection	Untreated
Halogen Free	Yes
Operating Temperature	-40 ... 100 °C

Dimensions

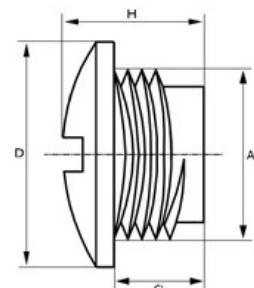

RND Type	AG	GL	D	H	Thread Size	Thread Length	Colour	Colour Code	Pitch
RND 465-01293	25 mm	10.5 mm	30 mm	15.5 mm	M25	10.5 mm	Black	RAL 9005	1.5 mm
RND 465-01311	20 mm	9 mm	25 mm	13 mm	M20	9 mm	Light Grey	RAL 7035	1.5 mm
RND 465-01315	20 mm	9 mm	25 mm	13 mm	M20	9 mm	Black	RAL 9005	1.5 mm
RND 465-01319	12 mm	8.5 mm	15 mm	12.5 mm	M12	8.5 mm	Black	RAL 9005	1.5 mm
RND 465-01320	16 mm	8.5 mm	19 mm	13 mm	M16	8.5 mm	Light Grey	RAL 7035	1.5 mm
RND 465-01323	16 mm	8.5 mm	19 mm	13 mm	M16	8.5 mm	Black	RAL 9005	1.5 mm
RND 465-01324	25 mm	10.5 mm	30 mm	15.5 mm	M25	10.5 mm	Light Grey	RAL 7035	1.5 mm
RND 465-01329	18.6 mm	9 mm	22 mm	13 mm	PG11	9 mm	Light Grey	RAL 7035	1.41 mm
RND 465-01331	15.2 mm	8.5 mm	19 mm	13 mm	PG9	8.5 mm	Black	RAL 9005	1.41 mm
RND 465-01332	12.5 mm	8.5 mm	15 mm	12.5 mm	PG7	8.5 mm	Black	RAL 9005	1.27 mm
RND 465-01333	15.2 mm	8.5 mm	19 mm	13 mm	PG9	8.5 mm	Light Grey	RAL 7035	1.41 mm
RND 465-01334	18.6 mm	9 mm	22 mm	13 mm	PG11	9 mm	Black	RAL 9005	1.41 mm
RND 465-01335	12.5 mm	8.5 mm	15 mm	12.5 mm	PG7	8.5 mm	Light Grey	RAL 7035	1.27 mm
RND 465-01336	12 mm	8.5 mm	15 mm	12.5 mm	M12	8.5 mm	Light Grey	RAL 7035	1.5 mm