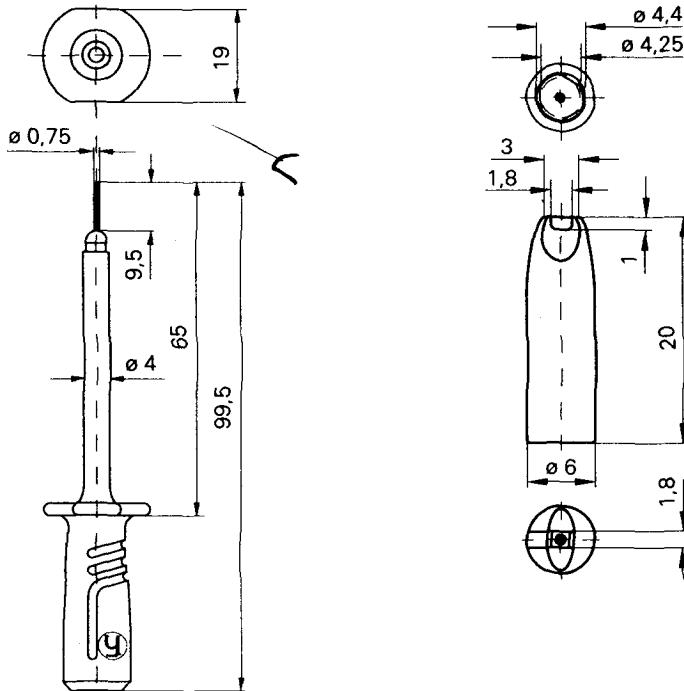


RS Stock No  
185-4993Colour  
Black/Red

Test probe with elastic shatter-proof insulated sleeve and slim, **spring-mounted** stainless steel tip, 0.75 mm in diameter. This ensures **constant contact pressure without slipping off**, even on the smallest measuring points. Spring-mounted 4 mm dia. connectors and measuring leads can be plugged into the **4 mm dia. socket connection**. Contact safety up to 1000 V is guaranteed when using shock-proof measuring leads (MLB ...) (refer to the range of safety equipment up to 1000 V).

**Tip guard and IC tab.** The tip of the needle is covered, thus **preventing injury** when this guard is clipped onto the test probes PRÜF 2, PRÜF 2 S and PRÜF 260. The guard also **prevents probes from slipping off measuring points** and **ICs are contacted without shorting**.

#### Technical data

Connector	ø 4 mm						
Test probe	spring-mounted						
Volume resistance (max.)	50 mΩ						
Permissible temperature range	-25 °C ... +80 °C						
Colour index*	<table> <tr> <td>black</td><td>-100</td></tr> <tr> <td>red</td><td>-101</td></tr> <tr> <td>transparent</td><td>-001</td></tr> </table>	black	-100	red	-101	transparent	-001
black	-100						
red	-101						
transparent	-001						

RS Components shall not be liable for any liability or loss of any nature (howsoever caused and whether or not due to RS components' negligence) which may result from the use of any information provided in RS literature.