


DATA SHEET

Tripod LED work light, 2 x 20W, extendable up to 155cm, 3m cable. IP65 waterproof LED construction site spotlights. Outdoor use. Ideal for construction sites, jobs, parties, and garden barbecues.

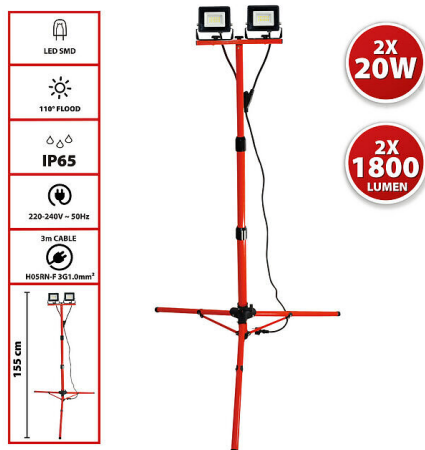

8 003910 141063

PACKING	INNER	MASTER
	 pcs	 pcs
Colour box	4	4



TECHNICAL DATA

Power supply	220V AC
Power supply provided	YES
Type of power supply provided	POWER CABLE
Lighting source	2835 SMD LED
Lighting power (W)	2x20
Electricity consumption (W)	40
Lumen	3600
IRC	>70
Light colour	4000K
Light beam	DIFFUSE
LED lifespan (hours)	15000
Beam angle (°)	110°
Power cord length (cm)	300
Cable section	H05RN-F 3G1.0mm2
Switch	NO
Functions	ON / OFF
Plug	Type E / F - 2 pin (EU Hybrid)
IP Protection	IP65
Insulation class	I
Dimmability	NO
Color	RED
Material	ALUMINIUM
EPREL code form	2528802
Product container (energy class)	F
Epel PDF file	https://storage.onpage.it/2aad3db35f9776ff82da6673dc10d80dd107f088/Fiche_2528802_EN.pdf
Link db eprel	https://eprel.ec.europa.eu/qr/2528802
Accessories included	Cable
Warranty	2 YEARS
Width (mm)	800
Depth (mm)	110
Height (mm)	105
Net weight (Kg)	1.766

DATA SHEET



Tripod LED work light, 2 x 20W, extendable up to 155cm, 3m cable. IP65 waterproof LED construction site spotlights. Outdoor use. Ideal for construction sites, jobs, parties, and garden barbecues.

DESCRIPTION



Power: The energy-saving 2x20W / 2x1800 lumen LED work light illuminates with natural white light (4000K) and provides optimal working conditions, even outdoors (IP65); average lifespan of 15,000 hours with low consumption. **Practically anywhere:** The portable lamp is useful for outdoor work, on the construction site, in the workshop, in the garden, at the campsite, or in the garage. The lights are also waterproof and suitable for both indoor and outdoor use. **Easy to use:** Extendable and easily adjustable metal tripod; wide base for greater stability. Maximum extension: 155cm. **Simple:** the LED work light is equipped with a long 3-meter neoprene power cable (H05RN-F 3G1.0mm²), which can be connected to any European socket (Schuko socket). **Beam angle:** 110° (floodlight); **Suitable for:** barbecues, photo shoots, party lighting, construction site lighting, garage lighting, etc.

LOGISTICS DATA

Packing type	Colour box
Pack length (mm)	190
Pack width (mm)	810
Pack height (mm)	170
Packed product weight (kg)	3.594
Inner length (cm)	83
Inner height (cm)	35
Quantity in inner	4
Gross weight inner (kg)	15.500
ITF INNER	18003910141060
Quantity in master	4
How many pieces on 80x120 pallet (pz)	48
INTRASTAT Code	94054210
DEEE	0.25

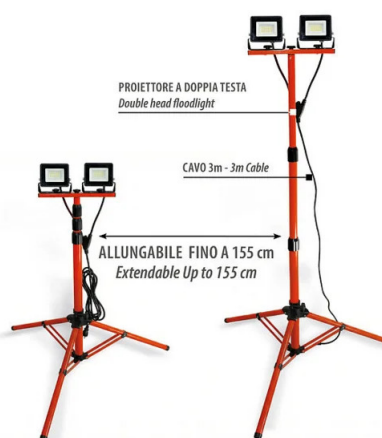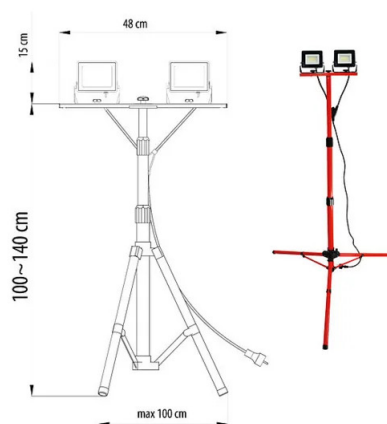

PRESA SCHUKO
220-240V~50Hz

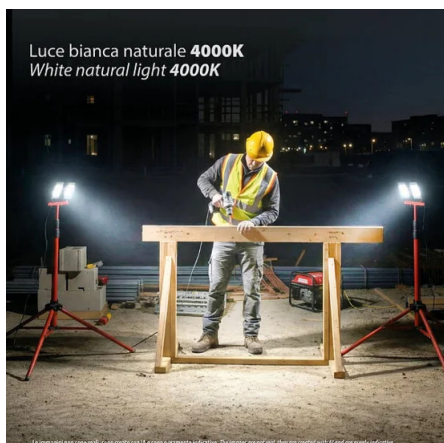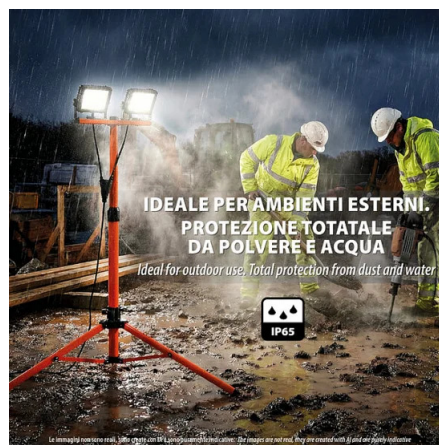

DATA SHEET

Tripod LED work light, 2 x 20W, extendable up to 155cm, 3m cable. IP65 waterproof LED construction site spotlights. Outdoor use. Ideal for construction sites, jobs, parties, and garden barbecues.

