


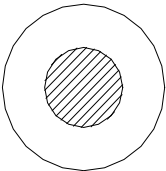

Datasheet

Product Name:	UL1213 16AWG
Product Discription:	UL1213 16AWG
Specification No.:	
Customer's Name:	

Description					Construction					
Rated Voltage:	Not specified				Conductor	Stranded Sliver plated copper				
Rated Temperature:	105°C, 60 °C Oil				Size(AWG)	16				
Reference Standard:	UL758				Construction(±0.015mm)	19/0.287				
Cross Section					Stranded Dia.(mm)Ref.	1.44				
					Insulation Material	PTFE				
					Insulation Color	ANY COLOR				
					Ave Thickness(mm)	0.25				
					Insulation Dia.(±0.10mm)	2.03				
Marking					Remark:					
No marking on the cable jacket, have UL label on the Reel.					9108475 White		9108487 Red			
					9108481 Green		9108490 Yellow			
					9108484 Black					
Applications					Characteristics				Customer Approve	
Internal wiring where not subjected to mechanical abuse, Oil Resistant 60 deg C.					Test Item	Standard Value				Seal & Stamp
					Test Material	PTFE(ROHS)				
					Insulation resistance(20°C MΩ*m)	1000				
					Vol. Tesr(AC.V.60S) (V)	2000				
Flammability Test	Horizontal flame									
Max.DC Resistance(20°C Ω/km)	14.8(MAX)									
Revisions					Signature: Date:					
Version	Description	Drawn by	Approved by	Date						
0	New document issue	Danniel	Jason	14/12/2015						