




1RZ-11/32

**11/32" Combination Ratcheting
Wrench with Chrome Finish 150
mm**



PRODUCT DETAILS

- Open end angle 15° with a slimmer head for improved accessibility
- Ring end angle 15° for knuckle clearance or better grip
- 5° action angle
- Switch for quick change of right and left direction
- Larger and bi-directional size marking for easy identification
- Ratchet in the ring for high productivity application
- 12-point Dynamic-Drive™ profile provides longer life for screws and nuts
- Chrome plated micro-matte finishing provides high quality surface
- High-performance alloy steel
- Standards: ISO 1711-1 and DIN 3113

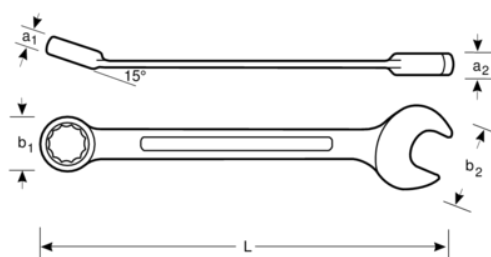

Follow the Fish!



PRODUCT ATTRIBUTES

Product		L	a2	a1	b1	b2	
1RZ-11/32	11/32 in	150 mm	6.9 mm	4.9 mm	18.4 mm	18.8 mm	36 g

