



Brand of NTN corporation

Technical data

EXFE215

Bearing units




Grey cast housing, radial insert ball bearing with eccentric locking collar, seal with slinger

KIT CONTENT

EX215G2, FE215

VISUAL (S)

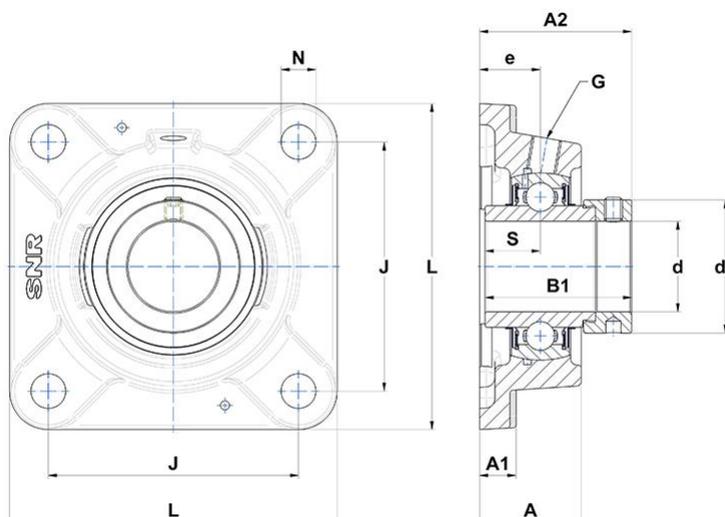

PRODUCT DEFINITION

Brand	SNR
A - Housing height	59 mm
A1 - Housing foot height / flange height	20 mm
A2 - Total height from mounting surface	96,1 mm
B - Width of Inner Ring	74,6 mm
B1 - Overall width Inner Ring	92,1 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

d - Shaft diameter	75 mm
d1 - Outer dia of eccent. Lock. collar / nut of adapter sleeve	102 mm
e - Distance mounting surface to bearing center	41,3 mm
G - Grease fitting	R1/8"
J - Mounting holes distance	153 mm
L - Housing width / diameter	197 mm
N - Mounting hole dimension	23 mm
S - Distance front side/bearing centre	37,3 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	66000000 mN
C0 - Static load rating	49500000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Mass	6,89 kg
Recommended tightening torque for set screw	22 N-m

