



AOXLED5



Features

Modern fully enclosed surface luminaire with curved low profile appearance

This is a widely used style of fitting within the educational sector

Steel body with polycarbonate diffuser and plastic end caps

34W exceeds performance of 1x49W T5

LED lifespan L70 54,000 hours

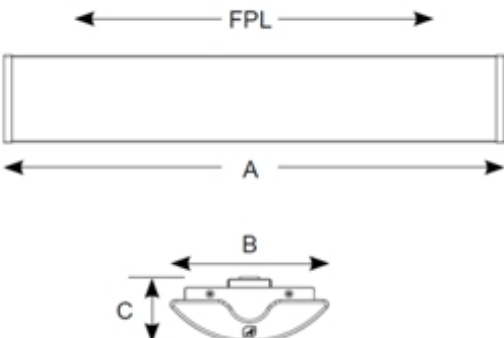
General Information

Lamp Type	LED
Colour / Finish	White
IP Rating	IP40
IK Rating	IK07
Class Protection	1
Internal / External	Internal
Surface / Recessed / Suspended	Surface
Warranty (Years)	5
CE Mark	Yes
Length (mm)	1470
Width (mm)	165
Height (mm)	70

Technical Information

Wattage	34W
Lumens Delivered	3668lm
Lm/W	108lm
CRI	Ra 80
CCT	4000K
Input	230V
Hertz	50/60Hz
Operating Temp	-20°C to 50°C

Datasheet generated from <https://onetimepim.com> last updated Friday, March 26, 2021 11:29:38 AM

	Code	A	B	C	FPL
	AOXLED4	1190	165	70	1084
	AOXLED5	1470	165	70	1384
	AOXLED2X4	1190	165	70	1084
	AOXLED2X5	1470	165	70	1364