

# Front plate - SI-FP-R1A-U1A/0,7

1404512

<https://www.phoenixcontact.com/gb/products/1404512>



Please be informed that the data shown in this PDF document is generated from our Online Catalog. Please find the complete data in the user documentation. Our General Terms of Use for Downloads are valid.

---

Front plate with contact inserts, plastic with shroud, 1 x USB (socket/socket/0.7 m cable) type A;  
1 x RJ45, 8-pos. metal, CAT5e (socket/socket)



# Front plate - SI-FP-R1A-U1A/0,7



1404512

<https://www.phoenixcontact.com/gb/products/1404512>

## Commercial Data

Item number	1404512
Packing unit	1 pc
Minimum order quantity	1 pc
Sales Key	BF7EDX
Product Key	BF7EDX
Catalog Page	Page 710 (C-2-2019)
GTIN	4046356698528
Weight per Piece (including packing)	76.4 g
Weight per Piece (excluding packing)	76.4 g
Customs tariff number	85366990
Country of origin	DE

# Front plate - SI-FP-R1A-U1A/0,7

1404512

<https://www.phoenixcontact.com/gb/products/1404512>

## Technical Data


### Product properties

Product type	Data front plate
--------------	------------------

### Electrical properties

Rated current	1 A (USB A)
	max. 175 mA (RJ45, D-SUB 9, UL rating)

### Dimensions

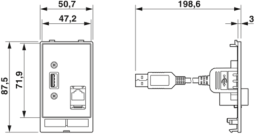Dimensional drawing	
Width	29.7 mm
Height	29.7 mm
Depth	20 mm

### Material specifications

Color	gray
Material	PBT (Front plate)

### Connector

Contact insert design	with 1x RJ45 Socket/socket, snap-in slot locking
	with 1x USB A 2.0 Socket/socket with 0.7 m cable, snap-in slot locking

### Environmental and real-life conditions

#### Ambient conditions

Degree of protection	IP20
Ambient temperature (operation)	-10 °C ... 60 °C

### Mounting

Assembly instructions	suitable for all mounting frames
-----------------------	----------------------------------


# Front plate - SI-FP-R1A-U1A/0,7

1404512


<https://www.phoenixcontact.com/gb/products/1404512>

## Drawings

Dimensional drawing

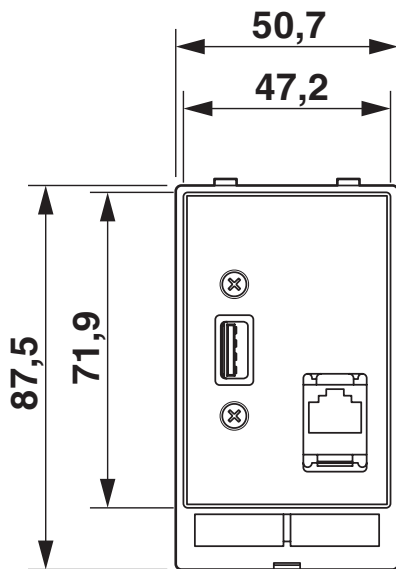

Dimensional drawing

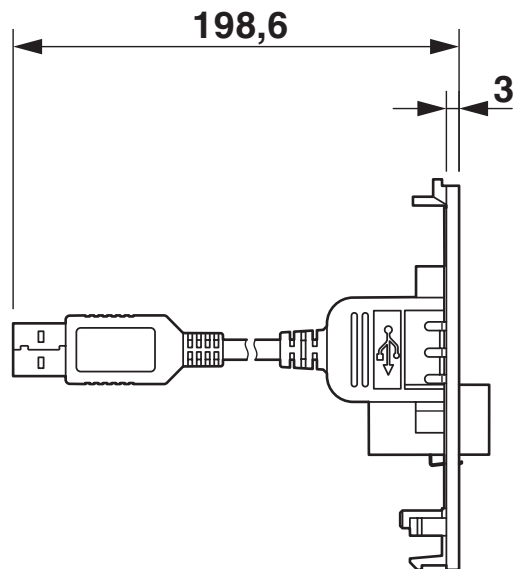

# Front plate - SI-FP-R1A-U1A/0,7

1404512

<https://www.phoenixcontact.com/gb/products/1404512>



## Approvals



**EAC**

Approval ID: RU C-DE.A\*30.B.01102

# Front plate - SI-FP-R1A-U1A/0,7



1404512

<https://www.phoenixcontact.com/gb/products/1404512>

## Classifications

### ECLASS

ECLASS-9.0	27189217
ECLASS-10.0.1	27182806
ECLASS-11.0	27182806

### ETIM

ETIM 8.0	EC000456
----------	----------

### UNSPSC

UNSPSC 21.0	39121300
-------------	----------

# Front plate - SI-FP-R1A-U1A/0,7



1404512

<https://www.phoenixcontact.com/gb/products/1404512>

## Environmental Product Compliance

China RoHS	Environmentally Friendly Use Period = 50 years For information on hazardous substances, refer to the manufacturer's declaration available under "Downloads"
------------	--

# Front plate - SI-FP-R1A-U1A/0,7



1404512

<https://www.phoenixcontact.com/gb/products/1404512>

## Accessories

### Snap-in markers

Snap-in markers - UCT-EM (20X7) - 0801494

<https://www.phoenixcontact.com/gb/products/0801494>



Snap-in markers, Sheet, white, unlabeled, can be labeled with: TOPMARK NEO, TOPMARK LASER, BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: snapped, lettering field size: 20 x 7 mm, Number of individual labels: 24

---

Phoenix Contact 2022 © - all rights reserved  
<https://www.phoenixcontact.com>

PHOENIX CONTACT Ltd  
Halesfield 13, Telford  
Shropshire, TF7 4PG  
01952 681700  
[info@phoenixcontact.co.uk](mailto:info@phoenixcontact.co.uk)