

PCB Enclosure

217 x 256 x 132.5 mm ABS/PC



FEATURES:

Designed for monitoring equipment, alarm system and process control
Integral guides and standoffs for vertical and horizontal PCB mounting
With cable knockouts
Place for padlock


SPECIFICATION:

Dimensions H x W x D	217 x 256 x 132.5 mm
Colour	grey/transparent-blue
Protection rating	IP 65
Material	ABS/PC
Temperature range	-20...+100 °C
Fire class	UL 94 HB



Art. Nr.

RND 455-00068

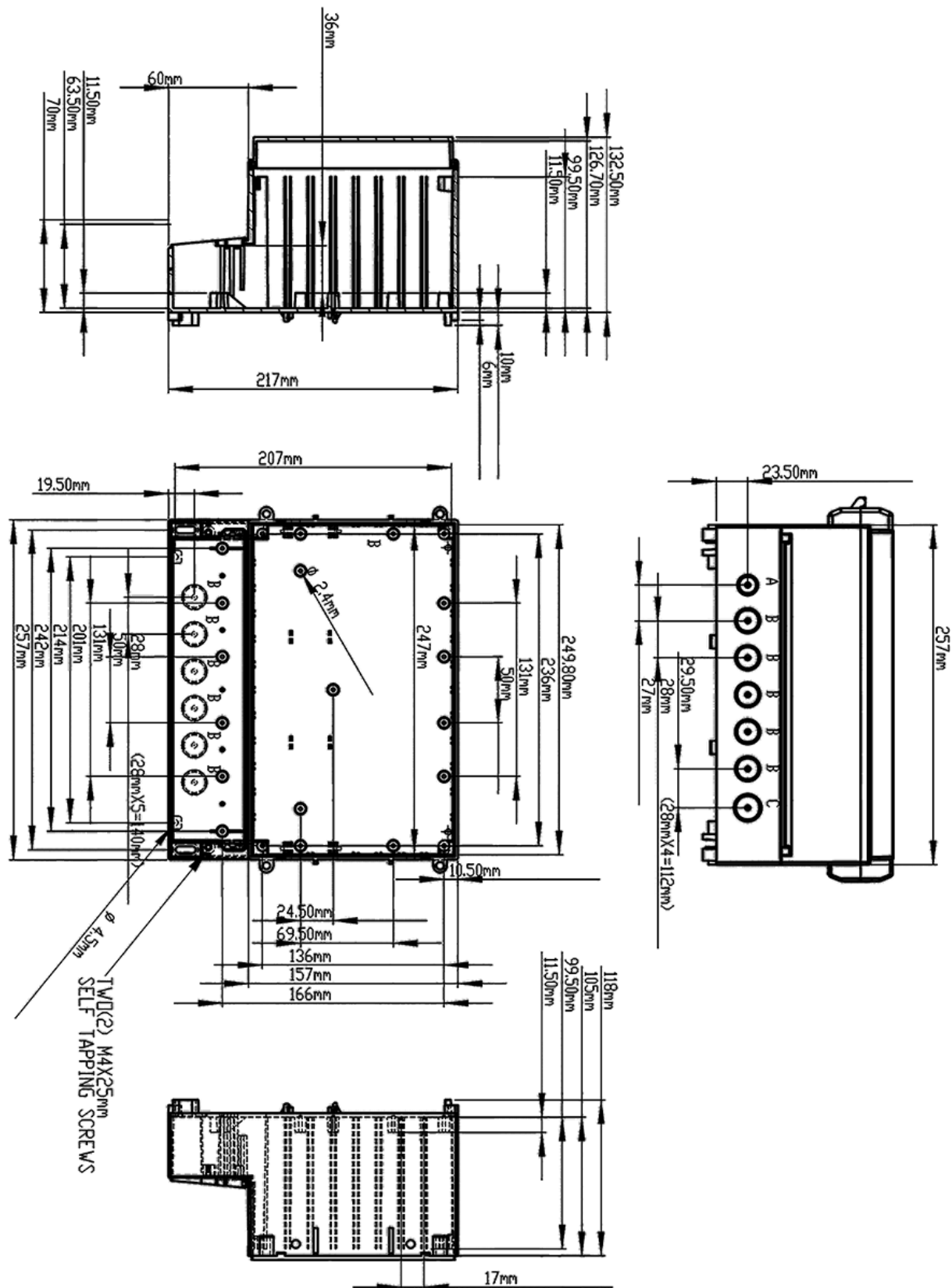

According to ISO 2768-m		
Measuring	DIM=L	Tolerances
0.5<L≤3.0mm		±0.1mm
3.0<L≤6.0 mm		±0.1mm
6.0<L≤30.0 mm		±0.2mm
30.0<L≤120.0 mm		±0.3mm
120.0<L≤400.0 mm		±0.5mm
400.0<L≤1000.0 mm		±0.8mm

	DIMENSION	CABLE GLAND
A	15.6mm	PG 9(OR M12)
B	19.0mm	PG 11(OR M16)
C	20.8mm	PG 13.5(OR M20)