


MSQ

一字单向调速阀

Slotted(non return)
speed controller

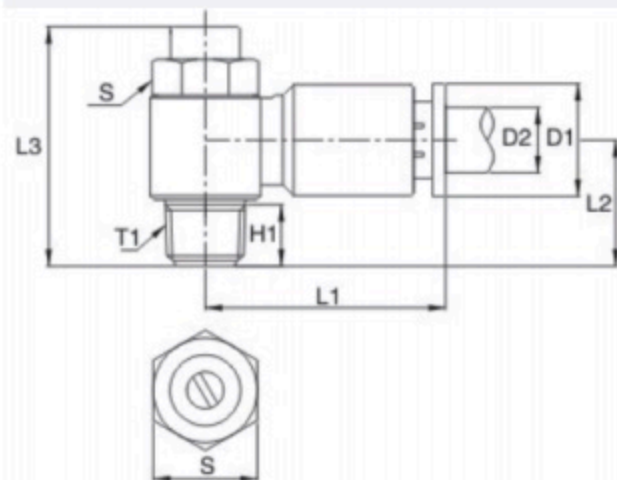

型号MODEL	L1	L2	L3	H	S	T	D1	D2
MSQ4-M5	18	10	22.5	3.6	8	M5		
MSQ4-01	21	15	30	7	12	R1/8	Φ8	Φ4
MSQ4-02	23	18	33.5	9	15	R1/4		
MSQ6-M5	21	11	22.5	3.6	8	M5		
MSQ6-01	23	15	30	7	12	R1/8		
MSQ6-02	24	18	33.5	9	15	R1/4	Φ12	Φ6
MSQ6-03	26	20	40.5	9.5	19	R3/8		
MSQ6-04	28	22.5	46.5	11.5	22	R1/2		
MSQ8-01	25	15	30	7	12	R1/8		
MSQ8-02	26	18	33.5	9	15	R1/4		
MSQ8-03	28	20	40.5	9.5	19	R3/8	Φ14	Φ8
MSQ8-04	30.5	22.5	46.5	11.5	22	R1/2		
MSQ10-01	27	16	30	7	12	R1/8		
MSQ10-02	28	19	33.5	9	15	R1/4	Φ16	Φ10
MSQ10-03	30	20	40.5	9.5	19	R3/8		
MSQ10-04	30	22.5	46.5	11.5	22	R1/2		
MSQ12-01	28	17	30	7	12	R1/8		
MSQ12-02	29	20	33.5	9	15	R1/4	Φ18	Φ12
MSQ12-03	31	21	40.5	9.5	19	R3/8		
MSQ12-04	32	22.5	46.5	11.5	22	R1/2		
MSQ14-03	37	21.5	40.5	9.5	19	R3/8	Φ21	Φ14
MSQ14-04	38	24	46.5	11.5	22	R1/2		
MSQ16-03	38	22.5	40.5	9.5	19	R3/8	Φ23	Φ16
MSQ16-04	39	25	46.5	11.5	22	R1/2		