




▽ ON 9MO

MODEL No.
VQ2※0※-5※1-XF


ENCLOSURE
NIL:DUST TIGHT
W :IP65(DUST TIGHT/LOW JETPROOF TYPE)

SEAL
0:METAL SEAL
1:RUBBER SEAL

TYPE OF ACTUATION
3:CLOSED CENTER
4:EXHAUST CENTER
5:PRESSURE CENTER

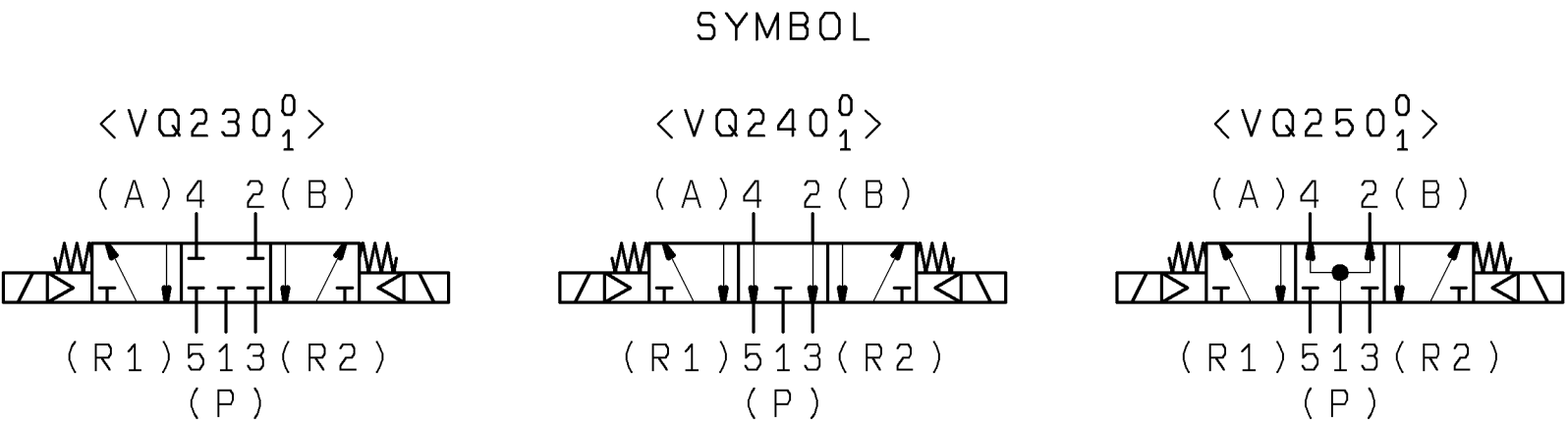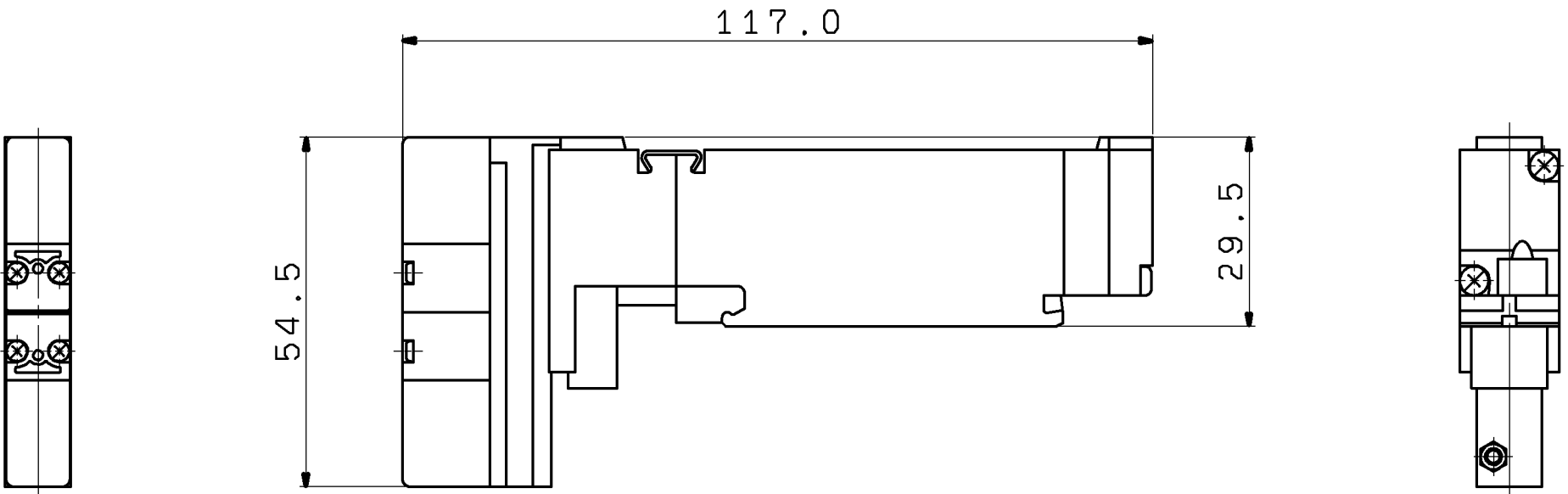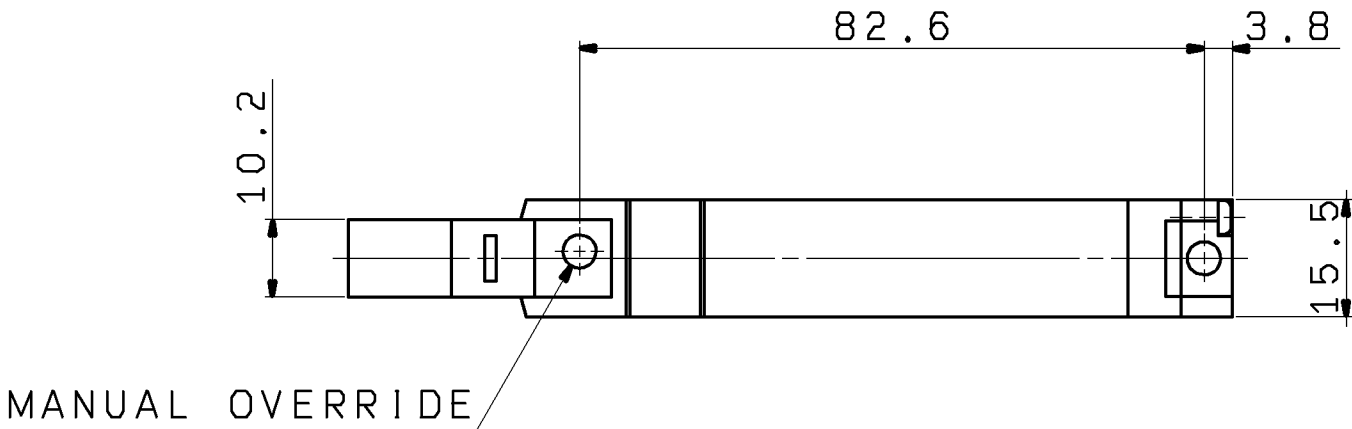

SPECIFICATIONS		
VALVE TYPE	5 PORT 3 POSITION AIR OPERATED VALVE	
VALVE CONSTRUCTION	METAL SEAL, RUBBER SEAL	
TYPE OF ACTUATION	CLOSED CENTER,EXHAUST CENTER,PRESSURE CENTER	
FLUID	AIR	
OPERATING PRESSURE RANGE	METAL SEAL	0.1 TO 0.7MPa
	RUBBER SEAL	0.2 TO 0.7MPa
AMBIENT&OPERATING FLUID TEMPERATURE	-10 TO 50°C(NON FREEZE)	
VOLTAGE TOLERANCE	-10 TO 10%	

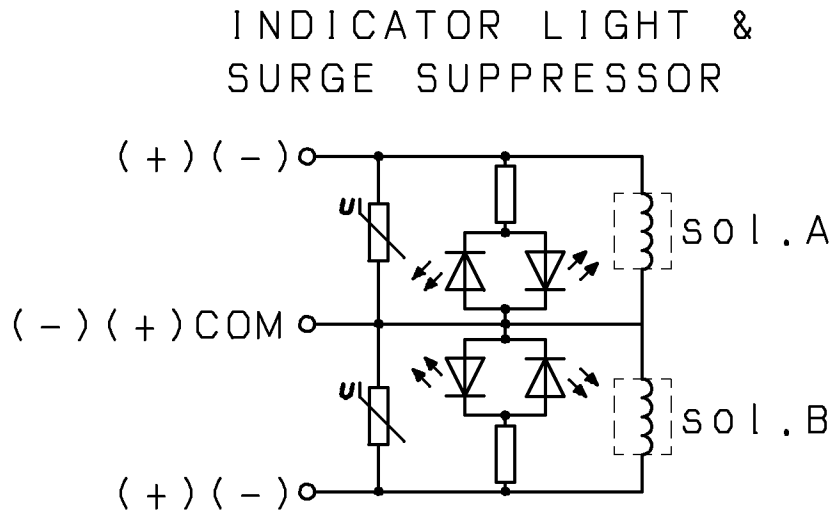

RATED VPLTAGE:24VDC

SPECIAL REQUIREMENT
NO POLARITY

- NOTES
- UNLESS OTHERWISE NOTED ALONG WITH A SEPARATE CONTRACT OR AGREEMENT WITHIN THE PRODUCT SPECIFICATIONS, THE SAFETY INSTRUCTIONS SPECIFIED IN THE PRODUCT CATALOG ARE APPLIED.PLEASE CONTACT YOUR LOCAL SMC SALES OFFICE FOR FURTHER DETAILS.
 - CE/UKCA MARKED PRODUCT.
[THE RELEVANT TCF IS AVAILABLE AS]
STANDARD PRODUCT SERIES.
 - DIMENSIONS ARE IN MILLIMETERS.