

## Uncoated cut resistant glove engineered with hppe-reinforced spandex


Showa 234X gloves are designed to provide exceptional protection in high-risk environments. Featuring a Level D cut resistance rating according to EN 388:2016 standards, they ensure reliable protection against cuts & abrasions. The 15 gauge seamless knit spandex liner is reinforced with HPPE for added strength & durability.

### Features

- ▲ Cut resistant: Level D / A4
- ▲ Lightweight, 15 gauge seamless knit spandex liner with HPPE
- ▲ Light contact heat protection up to 100°C
- ▲ Food handling approved
- ▲ Lightweight, supple liner with breathable open back design
- ▲ Cooling and breathable HPPE properties reduce perspiration and keep hands dry
- ▲ Designed for use in high cut risk areas such as food processing & food service industries
- ▲ Ambidextrous and launder-able for multiple use, less waste and cost reduction



### Certifications

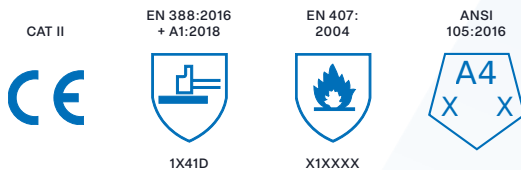

### Suitable industries & applications

#### Industries

- ▲ Food Production
- ▲ Automotive
- ▲ Construction
- ▲ Waste and Recycling

#### Applications

- ▲ Component and Product Assembly
- ▲ Food Preparation and Handling
- ▲ Salvage and Material Refinement
- ▲ Glass and Glazing

#### Europe

sales@globus.com  
+44 (0)161 877 4747  
+44 (0)161 877 4746

#### Middle East & Africa

sales.gcc@globusgroup.com  
+971 4 882 9962  
+971 4 882 9963

#### Americas

salesusa@globusgroup.com  
+1 83 337 54747



CUT PROTECTION

HEAT PROTECTION

Uncoated cut resistant glove engineered with hppe-reinforced spandex

#### Product information

<b>Materials</b>	Liner:	13 Gauge Engineered HPPE, Spandex, HPPE
	Coating:	Uncoated
<b>Colour</b>	Grey	
<b>Cuff Style</b>	Elasticated Knit Wrist	

#### Ordering information

<b>S</b>	SHO234X1	Items per Pack 1 x Pieces
<b>M</b>	SHO234X2	
<b>L</b>	SHO234X3	Items per Case 12 x Pieces
<b>XL</b>	SHO234X4	
<b>XXL</b>	SHO234X5	

#### Additional information

##### Certification legend



or click [here](#)

##### Declaration of conformity



or click [here](#)

##### View product online



or click [here](#)

#### Europe

sales@globus.com  
+44 (0)161 877 4747  
+44 (0)161 877 4746

#### Middle East & Africa

sales.gcc@globusgroup.com  
+971 4 882 9962  
+971 4 882 9963

#### Americas

salesusa@globusgroup.com  
+1 83 337 54747

**Globus Group**, T2 Trafford Point, Twining Road, Trafford Park, Manchester, M17 1SH, UNITED KINGDOM  
**Globus EMEA FZE**, Jafza One, Tower A, Office 2201, Jebel Ali, PO Box 61195, Dubai, UNITED ARAB EMIRATES  
**Globus Americas LLC**, 45 Rockefeller Plaza, Suite 2000, New York City, New York, 10111, USA

The descriptions, characteristics, applications and photos are given for information purposes and do not constitute a contractual commitment.  
The manufacturer reserves the right to make any modifications it deems necessary.

