


Deep groove ball bearings, single row, shield on both sides

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			C	C_0	kN	r/min	kg	-	* - SKF Explorer bearing
45	75	16	22,1	14,6	0,64	20000	10000	0,25	6009-2Z *

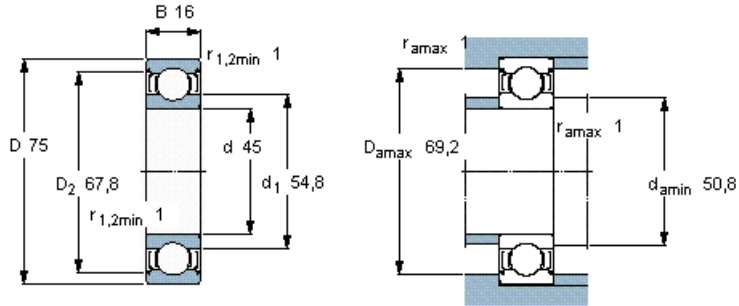

Calculation factors

k_r 0,025
 f_0 15