

CAP. WITH SCREW PLUG TERMINALS 21 POLE

Use with MVP12 / Exact12 UNIVERSAL

Art.No.: 8000-84759-0000000

Weight: 0.042

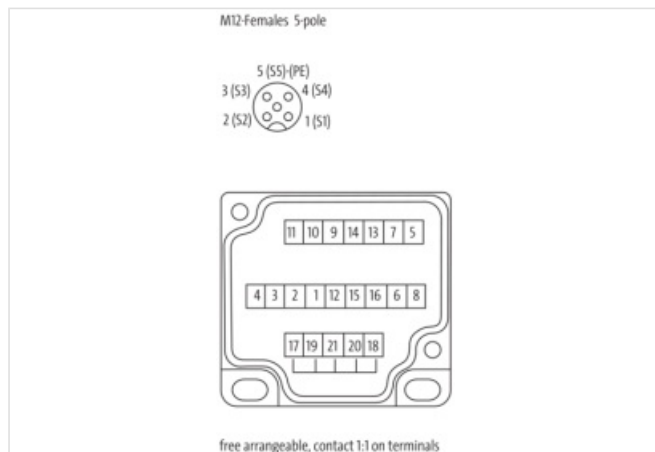
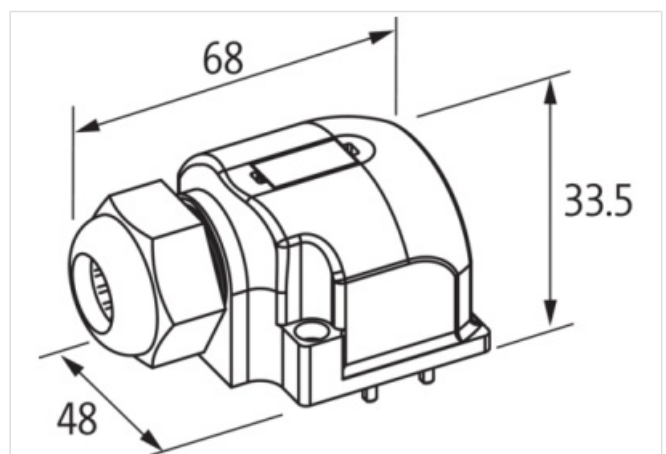
Country of origin: CZ

Model designation: MVZ-HSK M12 UNIVERSAL

Cap for 4-way distribution box, UNIVERSAL, 5-pole

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Product may differ from Image

**Commercial data**

URL Webshop	https://shop.murrelektronik.com/8000-84759-0000000
GTIN	4048879378536
ECLASS-6.0	27143423
ECLASS-6.1	27279219

ECLASS-7.0	27279219
ECLASS-7.1	27279219
ECLASS-8.0	27279219
ECLASS-8.1	27279219
ECLASS-9.0	27440111
ECLASS-10.0.1	27440111
ECLASS-10.1	27440111
ECLASS-11.0	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ECLASS-13.0	27440111
ECLASS-14.0	27440111
ETIM-5.0	EC002585
ETIM-6.0	EC002585
ETIM-7.0	EC002585
ETIM-8.0	EC002585
EAN	4048879378536

Electrical data | Supply

Total current max.	8 A
--------------------	-----

Installation

Connection cross section max.	1.5 mm ²
AWG number max.	16

Installation | Connection

Connection	Screw plug-in terminals
------------	-------------------------

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	Plastic
------------------	---------

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	80 °C

Connection type 2

Family construction form	Cap
No. of poles	21
Family construction form	M12
No. of poles	5
Coding	A
Gender	female
Color contact carrier	black