

IP65 FLEXIBLE LED TAPE +FLEX 160 HIGH CRI



8.2W/M



up to
1089LM/M



IP65



Recycleable
Cardboard




>95Ra



3000K, 4000K
6000K



50mm
Cut Points

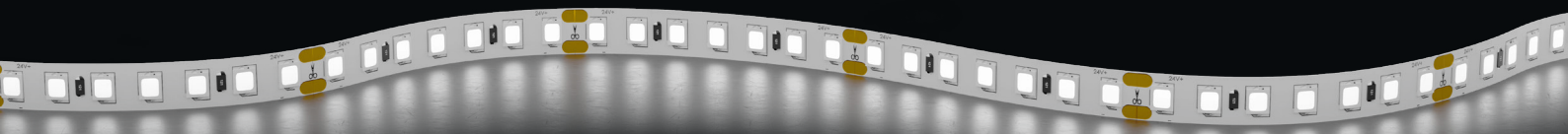

FEATURES

- High CRI >95Ra
- Available in three different colour temperatures
- Industrial grade adhesive backing tape
- Working temperature -20°C - +45°C
- Humidity 40% - 70% RH
- 3 years warranty

SPECIFICATIONS

Stock Code	0295-304	1278-778	1712-930
Part Code	C0-2-160-65-95	D0-2-160-65-95	F0-2-160-65-95
Voltage	24VDC	24VDC	24VDC
Power Consumption	8.2W/M	8.2W/M	8.2W/M
Lumen Output	1066LM/M	1066LM/M	1089LM/M
Efficacy	130LM/W	130LM/W	133LM/W
Tone (CCT)	3000K ●	4000K ●	6000K ●
LED/metre	160	160	160
LED Pitch	6.25mm	6.25mm	6.25mm
Cut Points	50mm	50mm	50mm
CRI	>95Ra	>95Ra	>95Ra
IP Rating	65	65	65
Dimensions	5000 x 8 x 2.2mm	5000 x 8 x 2.2mm	5000 x 8 x 2.2mm



3000K



4000K



6000K

IP65 FLEXIBLE LED TAPE +FLEX 160 HIGH CRI



COMPATIBILITY



CONTROL METHODS

- Bluetooth (Apps, Voice Control) - BLE-15A
- Remote Control - SCD107W

SUGGESTED DRIVERS

Up to 1 M	Up to 5 M	Up to 10 M
Power supplied from ONE end	Power supplied from ONE end	Power supplied from the MIDDLE or BOTH ends
Non Dimmable	Non Dimmable	Non Dimmable
PCV2420	PCV2450	PCV24101
Mains Dimmable	Mains Dimmable	Mains Dimmable
UVC2425TD	UVC2450TD	UVC24100TD
DALI Dimmable	DALI Dimmable	DALI Dimmable
DA-30-24	DA-50-24	DA-100-24

*IP rated and other options available. Contact us for more information.

MECHANICAL DIAGRAM

