



plug-in fittings

3126 plug — fractional inch

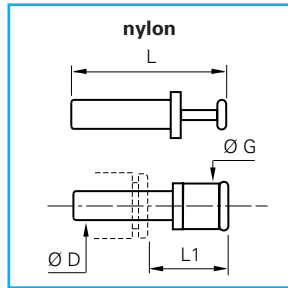



ØD in		G in	L in	L1 in	
1/8	3126 53 00	.24	1.30	.85	.05
5/32	3126 04 00	.16	1.18	.61	.04
3/16	3126 55 00	.27	1.36	.79	.06
1/4	3126 56 00	.32	1.44	.87	.06
5/16	3126 08 00	.39	1.38	.69	.07
3/8	3126 60 00	.46	1.67	.87	.10
1/2	3126 62 00	.58	1.91	.85	.18

3126 plug — metric

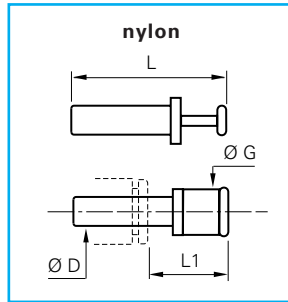

ØD mm		G mm	L mm	L1 mm	
3	3126 03 00	6	25	13.5	.001
4	3126 04 00	4	30	15.5	.001
6	3126 06 00	8	33	16.5	.001
8	3126 08 00	10	33	17.5	.002
10	3126 10 00	12	42	21	.003
12	3126 12 00	14	45	22	.004
14	3126 14 00	16	49	23.5	.005


3122 barbed connector — fractional inch

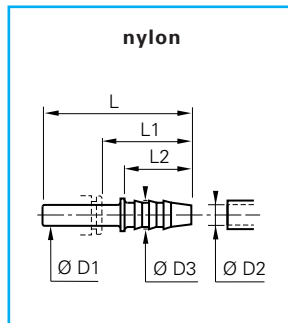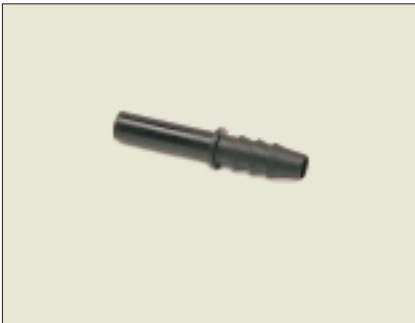

ØD1 in	ØD2 in	ØD3 in		L in	L1 in	L2 in	
5/32	.12	.20	3122 04 53	1.46	.98	.67	.11
5/32	.20	.28	3122 04 05	1.46	.98	.67	.11
1/4	3/16		3122 56 55*	1.65	1.00		.21
5/16	.25	.34	3122 08 56	1.55	.83	.67	.04
5/16	.32	.39	3122 08 08	1.75	1.02	.87	.04
3/8	.32	.39	3122 60 08	1.97	1.16	.87	.11

*nickel-plated brass
dimensions for ØD2 are I.D. of the tube.

3122 barbed connector — metric

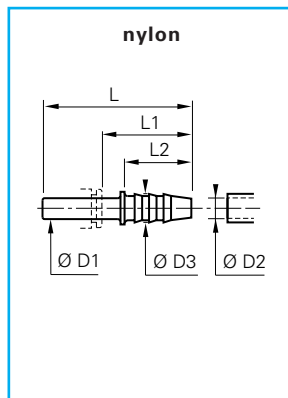

ØD1 mm	ØD2 mm	ØD3 mm		L mm	L1 mm	L2 mm	
4	3.2	5	3122 04 53	37	25	17	.002
4	5	7	3122 04 05	37	25	17	.003
6	5	7	3122 06 05	39	25	17	.004
8	6.3	8.5	3122 08 56	39.5	21	17	.005
8	8	10	3122 08 08	44.5	26	22	.005
10	6.3	8	3122 10 56	45	24.5	17	.005
10	8	10	3122 10 08	50	29.5	22	.006
12	8	10	3122 12 08	50	26	22	.008
12	10	12	3122 12 10	48.5	25.5	22.5	.014
12	12.5	14.5	3122 12 62	57	34	22.5	.019
14	12.5	14.5	3122 14 62	59.5	34.5	22.5	.022
14	14	16	3122 14 14*	59.5	34.5	22.5	.022

*nickel-plated brass