


DATASHEET



FLN20

230V IP65 20W LED FLOOD

www.mlaccessories.co.uk

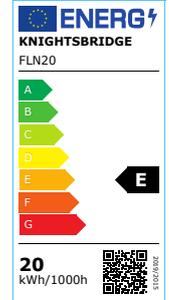

MLA PART CODE	FLN20
DESCRIPTION	230V IP65 20W LED FLOOD
NET WEIGHT (KG)	0.372
FINISH	Black
DIFFUSER	Clear
DIMENSIONS (MM)	Height - 129 Width - 135 Depth - 28 Projection - 148 Overall Height - 186
CONSTRUCTION	Construction - Die-cast aluminium Construction 2 - & polycarbonate
CLASS	I
IP RATING	IP65
WATTAGE (W)	20
LAMP TECHNOLOGY	LED
LAMP INCLUDED	Yes
LUMENS (LM)	2240
LUMEN TOLERANCE	10%
EFFICACY (LM/W)	120.23
CIRCUIT WATTAGE (W)	18.65
CCT	4000K
LIGHT COLOUR	Cool White
CRI	>80
SDCM	<6
RUNNING CURRENT (A)	0.101
DISPLACEMENT FACTOR	>0.7
SVM	0.011
PST-LM	0.005
BEAM ANGLE (DEGREES)	100
LIFE SPAN (HRS)	30,000

L70B50 LIFESPAN (HRS)	30,000
DIMMABLE	No
OPERATING TEMPERATURE	-20~40°C
INPUT VOLTAGE	230V 50Hz
CABLE GLAND INCLUDED	Compression gland
WARRANTY	3year(s)
MANUFACTURED IN ACCORDANCE WITH	BS EN 60598
ORIGIN OF MANUFACTURE	China
DECLARATION OF CONFORMITY (HELD ON FILE)	Yes
EAN	5056270811087

Date Created: 09/02/2022 11:14

