

Datasheet

Uninsulated Crimp Blade Terminal, 22 → 16 AWG

RS Stock number [208-2694](#)



Specifications:

1. Maximum Electric Current: (最大電流)

22-16AWG / 0.5-1.5mm²: 19A

16-14AWG / 1.5-2.5mm²: 27A

12-10AWG / 4-6mm²: 48A


2. Terminal Body: Copper (端子材質: 紅銅)

3. Insulation: (護套材質:)

4. Plating: Tin (表面處理: 鍍錫)

NBT---Non-Insulated butted seam

NB---Non-insulated brazed seam

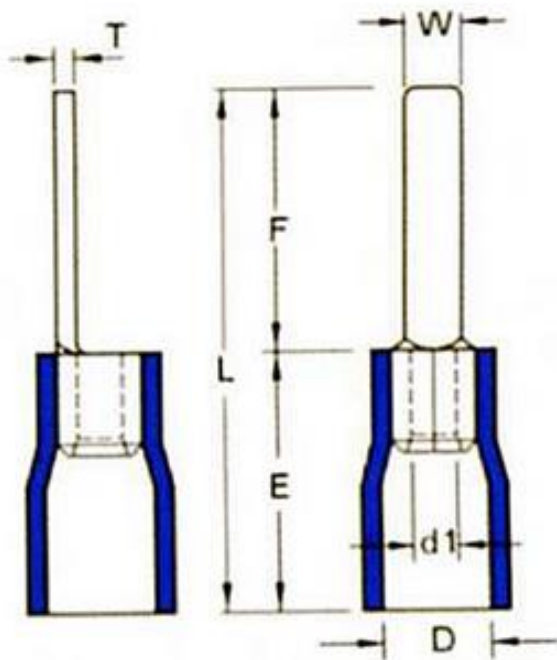

Insulation Colour	Wire Range Mm ² /Awg	Dimension (mm)
Blue	1.5-2.5mm ² /16-14AWG	2.5/18.0/28.0/10.0/4.5/2.3/0.8