


# Universal socket strip 3-fold with switch (type G)

Item-No.: 0201x0603230b-1 (1.5 m cord) | 0201x0603230b-3 (3 m cord)

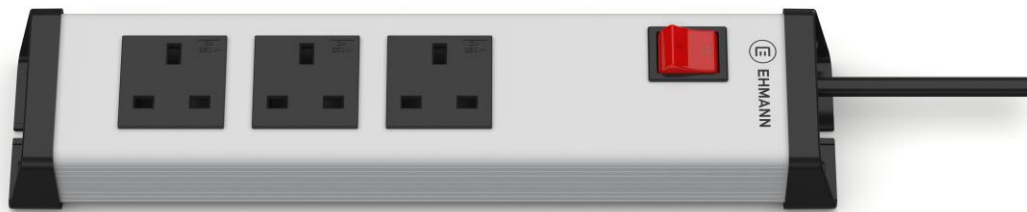


Robust plastic, grey

Built-in sockets (90° rotated), quadrangular

1,5 m power cord and angle plug (optional with 3 m power cord)


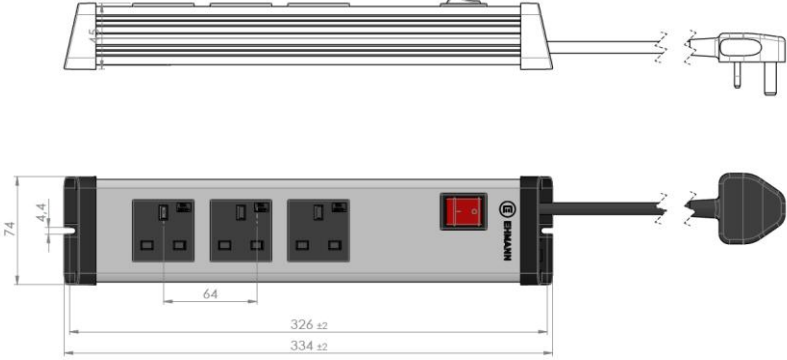
Expanded contact protection

End caps with mounting possibility

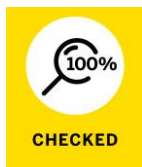

## Universal socket strip 3-fold with switch (type G)

### Technical data

3000 W Power	230 V ~ (+/- 10%) / 50 Hz Rated voltage	13 A Rated current
Power Cord: H05VV-F 3G 1.5 mm <sup>2</sup> Plug: BP1 British Standard Type G, BS 1363/A, angled Fuse: 13A fuse according to BS 1362 Sockets: Type G Switch: 2-pole, illuminated (red) Consumption per switch: < 0,5 W Safety class: IP20		
 <p>(similar illustration)</p>		
Item-No. 0201x0603230b-1 (1.5 m cord)    EAN 4012096011064    PU 10 Item-No. 0201x0603230b-3 (3 m cord)    EAN 4012096013464    PU 10		334 x 74 x 45 mm Dimensions (L x W x H) 326 mm Fixing Dimension