



All AMP MCP, RECEPTACLE AND TAB (105)

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

 
 
EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not reviewed for solder process capability

Product Compliance Disclaimer

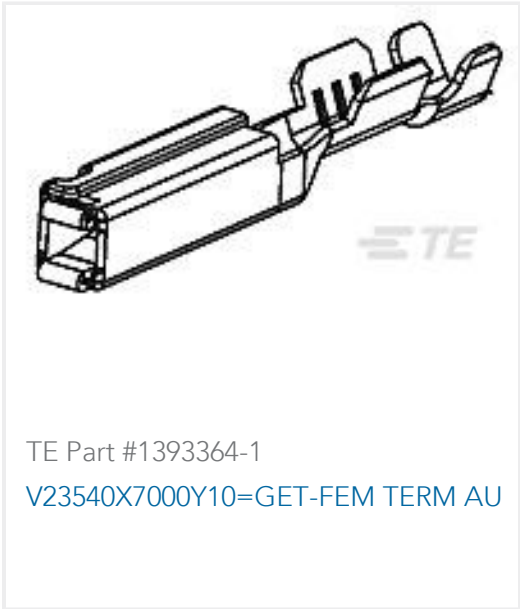
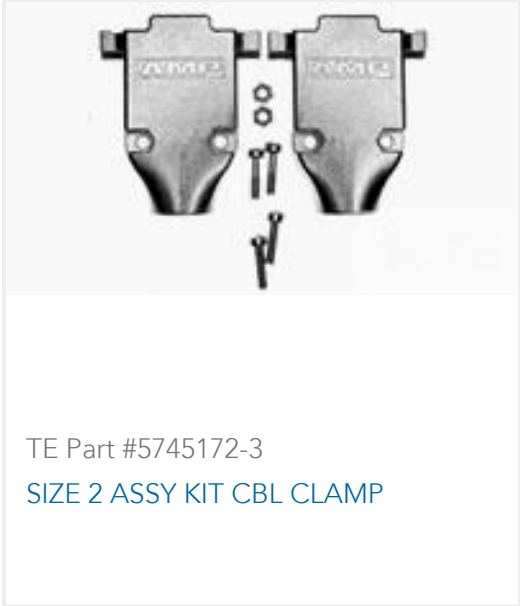
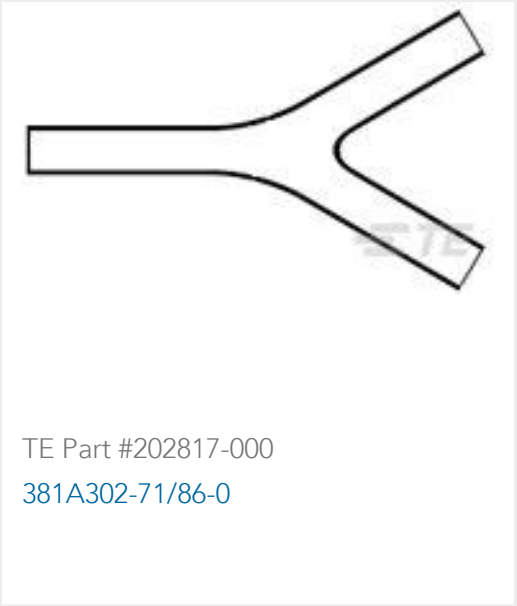
This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>



Compatible Parts

 TE Part # 2385319-1 EXTRACTION TOOL	 TE Part # 2385319-3 EXTRACTION TOOL	 TE Part # 2385319-2 EXTRACTION TOOL	 TE Part # 1-1579007-1 EXTRACTION TOOL
 TE Part # 2497553-1 GAUGE,CHECK TAB FOR AMP MCP 1.5K CONTACT	 TE Part # 2208746-1 28POS MQS REC	 TE Part # CAT-AM705-CH8173 AMP Unsealed Connector Housing	 TE Part # 4-1579016-0 ERGOGRIMP DIE SET MCP1.5K

Customers Also Bought

 TE Part #1393364-1 V23540X7000Y10=GET-FEM TERM AU	 TE Part #YDTS26W11-35PBV001 PLUG ASSY	 TE Part #1051018-1 2004 7985 00	 TE Part #275925-000 CWT-3806-W2
 TE Part #5745172-3 SIZE 2 ASSY KIT CBL CLAMP	 TE Part #745508-3 FERRULE SPLIT RING, HD	 TE Part #5745854-3 CABLE CLAMP KIT,SZ 1	 TE Part #202817-000 381A302-71/86-0
 TE Part #5414710001 TMS-SCE-1-1/2-2.0-9	 TE Part #359434-000 SO63-4-00		



Documents

Product Drawings

AMP MCP 1.5K, CONTACT

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1564980-3_A.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_1564980-3_A.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_1564980-3_A.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

Engineering Specification

English