



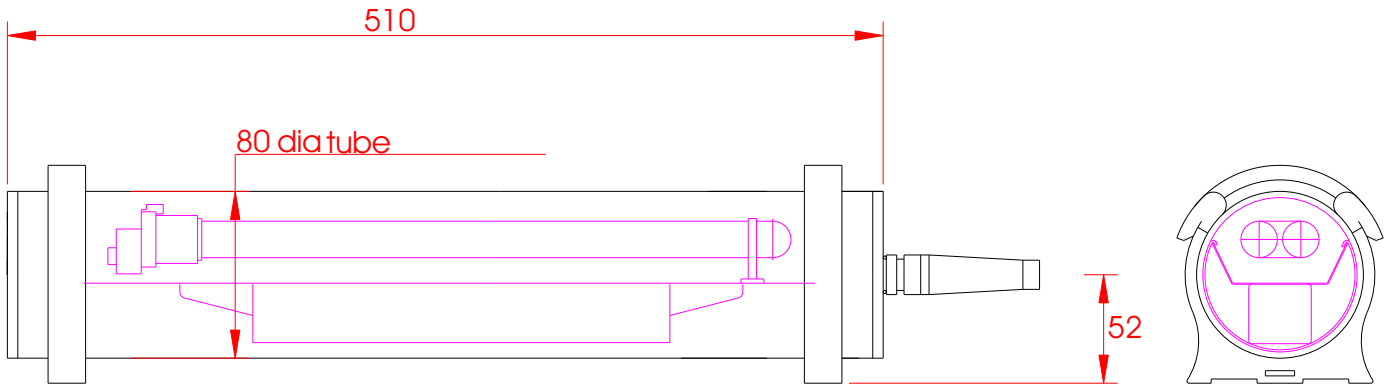

EDL Lighting Ltd

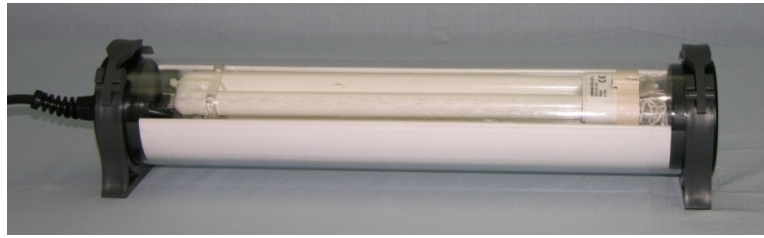

Version: Tubelight-80-IP67-36W-CFL-230/240V

RS Order Code: 794-3474

The waterproof tubelight is tested to Ip67 and comes complete with brackets and trailing lead. The main body tube is manufactured from impact resistant polycarbonate. This unit has many applications within the manufacturing and food industries as well as marine environments. The plastic end caps are secured using stainless steel screws to ensure not only a watertight seal but also a unit that will resist corrosion.

Main features:

Impact resistant polycarbonate tube
 Compact fluorescent tube
 Suitable for machine mounting - withstands coolant spray onto light unit
 Design facilitates ease of cleaning
 Trailing lead fitted as standard

High IP rating Ip67
 Clamps and ballasts included
 Other marine and waterproof applications

Can be used in dusty environments
 Clip on brackets securing straps - no tools needed

Made in United Kingdom- all spares available

Other voltages & wattages available

Primary Voltage: 230/240v 50/60 Hz
 End Cap material: Moulded PVC
 Ballast: High frequency Electronic
 Brackets Supplied: Yes
 Plug Fitted : No
 IP rating: IP67
 Fixing: Can be Horizontal or Vertically mounted
 RHOS Compliant: Yes

Lamp Type: Compact Fluorescent (CFL)
 Lamp Wattage: 36W
 Lamp Base: 2G11
 Trailing Cable: Yes approx 2.7m
 Switch Fitted: No
 Tube Material: Polycarbonate 80mm Dia
 Manufacturing Standard: BS EN 60598
 Wee Compliant: Yes

EDL Lighting Limited, Redbrook lane, Brereton, Rugeley, Staffs WS15 1QU

Telephone: +44(0)1889 582112

Fax: +44(0)1889 584012

Email: sales@edl-lighting.co.uk Website www.edl-lighting.co.uk