


Datasheet

HSS 40 mm 90° Countersink, 16.5mm Head Diameter, 3 Flutes

RS Stock number 423-826



Dimensions:

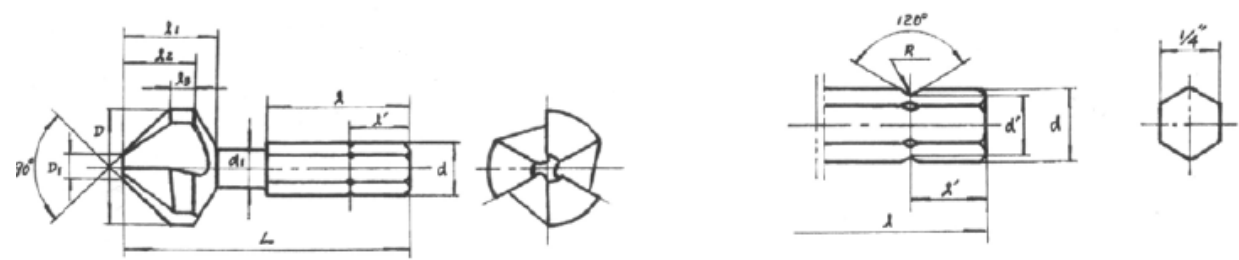

NOMINAL HEAD DIA.	OVERALL LENGTH (D)	SHANK LENGTH(l)	HEX SHANK DIA.(d)	POINT ANGLE	NO. OF FLUTE
6.3mm	31mm	21.5mm	7.15mm	90°	3
8.3mm	32mm	21.5mm	7.15mm	90°	3
10.4mm	34mm	21.5mm	7.15mm	90°	3
12.4mm	36mm	21.5mm	7.15mm	90°	3
16.5mm	40mm	21.5mm	7.15mm	90°	3
20.5mm	43mm	21.5mm	7.15mm	90°	3

Remarks:
- Material: HSS M2