


OPEN HOSE REELS FOR COMPRESSED AIR / STEEL

DVO series - Medium - Polyurethane braided hose



Part number	Length (m)	Flow rate (l/min)	Max. operating pressure (bar)	Net weight (Kg)	Male thread	Profile
DVO 1025IS	25.00	500.00	12.00	16,5	G3/8	ISO 6150B

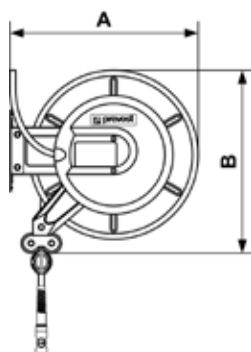

Part number	Dim. A (mm)	Dim. B (mm)	Ø int/ext (mm)
DVO 1025IS	460.00	447.00	10.00 / 14.00