



|               |                                                                               |
|---------------|-------------------------------------------------------------------------------|
| Category      | Battens and Weatherproofs                                                     |
| Application   | Ancillary, Commercial, Education, Healthcare, Hospitality, Industrial, Retail |
| Specification | Performance                                                                   |


# Tornado EVO

Tornado EVO CCT Multi Wattage 600mm

Code: ATORE2/1


## Increased Flexibility

Three side conduit entries allow for **enhanced flexibility** and **faster installations**

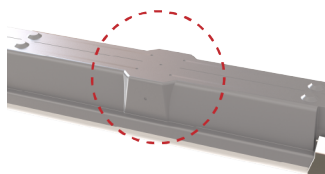


## Stable Mounting

Large installation bracket fixings ensure a more **secure** and **durable** mounting process.

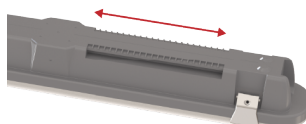

## Painless Install

Base supplied disassembled, with easy attach clips for easy installation.

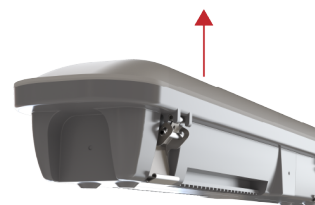

## PRODUCT FEATURES

- IP66 non-corrosive batten suitable for industrial applications and ancillary areas
- CCT selectable between 4000K, 5000K and 6500K and power selectable; offering a choice of 2 outputs, in one luminaire
- LED performance allows point-to-point replacement of existing fluorescent luminaires
- Whole luminaire illuminates during emergency operation rather than a small area, allowing less emergency versions required on an installation
- High efficiency up to 160 Lm/W
- Slim sloped diffuser design creates sleek appearance and offers greater light distribution
- Lockable heavy-duty stainless steel clips supplied as standard for added safety and security

## GENERAL INFORMATION

|                                  |                         |
|----------------------------------|-------------------------|
| Wattage                          | 9W/18W                  |
| Lumens Delivered                 | 1600lm - 3100lm (4000K) |
| Lm/W                             | 150lm/W (4000K)         |
| Beam Angle                       | 120                     |
| CRI                              | 80                      |
| CCT                              | 4000/5000/6500K         |
| Input                            | 220-240V                |
| Operating Temp                   | -20°C - 40°C            |
| SDCM                             | 3                       |
| Energy efficiency class          | D                       |
| Product Weight without Packaging | 0.76 kg                 |

## TECHNICAL INFORMATION

|                                |                     |
|--------------------------------|---------------------|
| Light Source                   | LED                 |
| Colour / Finish                | Grey                |
| IP Rating                      | IP66                |
| IK Rating                      | IK10                |
| Class Protection               | 1                   |
| Internal / External            | Internal / External |
| Surface / Recessed / Suspended | Ceiling, Suspended  |
| Lumen Depreciation             | L80 100,000h        |
| Warranty (Years)               | 7                   |
| CE Mark                        | Yes                 |
| Height                         | 81 mm               |



|                      |                                                                               |
|----------------------|-------------------------------------------------------------------------------|
| <b>Category</b>      | Battens and Weatherproofs                                                     |
| <b>Application</b>   | Ancillary, Commercial, Education, Healthcare, Hospitality, Industrial, Retail |
| <b>Specification</b> | Performance                                                                   |

# Tornado EVO

Tornado EVO CCT Multi Wattage 600mm

Code: ATORE2/1

