


DIN 7444

- Utilizzabili a percussione con mazza o martello pneumatico

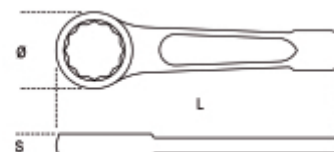

		art.	 mm	L mm	Ø mm	S mm	 kg	
		000780024	78 24	24	162	42,0	15,0	0,24
		000780027	78 27	27	180	47,0	16,0	0,27
		000780030	78 30	30	190	54,0	17,0	0,37
		000780032	78 32	32	190	54,0	17,0	0,35
		000780034	78 34	34	200	57,00	18,00	
		000780036	78 36	36	205	60,0	19,0	0,53
		000780041	78 41	41	225	66,0	20,0	0,70
		000780046	78 46	46	235	75,0	22,0	0,93
		000780050	78 50	50	250	80,0	24,0	1,15
		000780055	78 55	55	265	88,0	25,0	1,40
		000780060	78 60	60	275	94,0	26,0	1,60
		000780065	78 65	65	295	104,0	28,0	2,00
		000780070	78 70	70	325	110,0	33,0	2,90
		000780075	78 75	75	325	115,0	33,0	2,70
		000780080	78 80	80	350	126,0	36,0	3,90
		000780085	78 85	85	350	130,0	36,0	3,80
		000780090	78 90	90	390	152,0	39,0	5,10
		000780095	78 95	95	390	152,0	39,0	4,80
		000780100	78 100	100	420	155,0	43,0	6,60
		000780105	78 105	105	420	172,0	45,0	6,20
		000780110	78 110	110	450	172,0	47,0	8,20
		000780115	78 115	115	450	172,0	47,0	7,60
		000780120	78 120	120	490	194,0	53,0	9,80
		000780125	78 125	125	480	194,0	53,0	9,00
		000780130	78 130	130	520	205,0	57,0	13,50
		000780135	78 135	135	520	205,0	60,0	13,00
★		000780140	78 140	140	520	205,0	60,0	12,70
★		000780145	78 145	145	580	230,0	62,0	19,20
★		000780150	78 150	150	580	230,0	62,0	19,00
★		000780155	78 155	155	580	230,0	62,0	17,80
★		000780160	78 160	160	650	270,0	66,0	19,00
★		000780165	78 165	165	650	270,0	66,0	28,00
★		000780170	78 170	170	650	270,0	66,0	27,30
★		000780175	78 175	175	650	270,0	66,0	26,20
★		000780180	78 180	180	650	270,0	66,0	26,00
★		000780185	78 185	185	695	295,0	71,0	35,00
★		000780190	78 190	190	695	295,0	71,0	33,60
★		000780195	78 195	195	695	295,0	71,0	33,00
★		000780200	78 200	200	695	295,0	71,0	32,10
★		000780210	78 210	210	740	325,0	76,0	40,60
★		000780215	78 215	215	740	325,0	76,0	38,90
★		000780220	78 220	220	740	325,0	76,0	36,50
★		000780230	78 230	230	740	325,0	76,0	34,65