
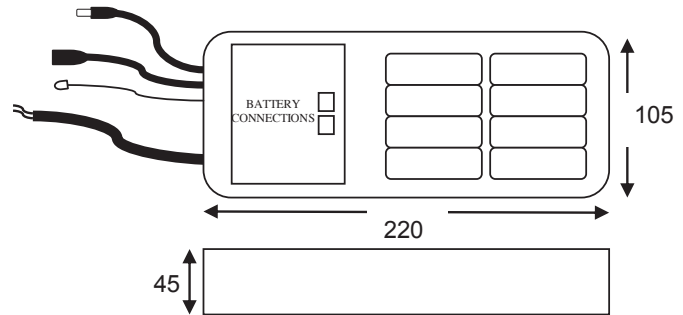


EMKIT Constant Current LED 23-50W, 36V Max maintained and non-maintained Emergency conversion kit.

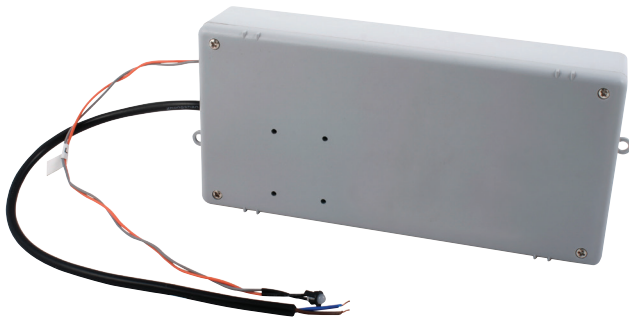

MLA part code:

EMKIT

Description:

23-50W 36V Max constant current LED Emergency conversion kit. Maintained and non-maintained operation with integral batteries (Driver required for maintained operation)

Weight (kg):

0.85

Wattage (W):

23-50

Overall dimensions (mm):

105 (h) 220 (w) 45 (d)

Charge Time (Initial):

24 Hrs

Discharge duration:

3 Hrs

Battery type:

2 x 9.6V 1500mAh Ni-Cd

Charging Current (mA):

80-130

Compatible with:

LEDMRC LEDPAN1 LEDPAN2 MRBLED PL23LED

Input voltage:

Mains 230V 50Hz

Construction:

Self-Extinguishing Polycarbonate

Driver required:

Yes for maintained operation

Class:

Class II

IP rating:

IP20

Warranty:

1 Year (excluding battery)

Supplied with:

250mm 2182Y 2 core cable (Mains Connection).
Driver & luminaire plug & Play.
Adapter leads provided

Dimmable:

No

Instruction sheet:

Yes

Origin of Manufacture:

China

Quality assurance system:

ISO 9001

Declaration of Conformity (held on file):

Yes

Manufactured in accordance with:

EN55015, EN61547, EN61000-3-2, EN61347-2-7,
EN61347-2-3 BSEN60598

