



SITOR fuse holder 1250 A 1250 V 1-pole with bolt terminal with fixing dimension 110 mm

Figure similar

Model		
product brand name		SETRON
product designation		LV HRC fuse system
design of the thread of the connection screw		M10
design of the product		LV HRC fuse base for screw fixing
General technical data		
number of poles		1
utilization category		Without
Supply voltage		
supply voltage		
• at AC		1 250 V
• at DC		1 250 V
Product details		
product component swivel-in mechanism		No
Connections		
tightening torque with screw-type terminals maximum		20 N·m
type of electrical connection		for mounting on mounting plate
• for main current circuit		Stud terminal
Mechanical Design		
height		153 mm
width		55 mm
fastening method		fixed mounting
fastening method bus-mounting		No
net weight		595 g
Approvals Certificates		
General Product Approval		other
		Environment



[Miscellaneous](#)

[Confirmation](#)

[Environmental Con-
firmations](#)

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
Information- and Downloadcenter (Catalogs, Brochures,...)
<http://www.siemens.com/lowvoltage/catalogs>
Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3NH5463>
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3NH5463>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)



http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NH5463

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

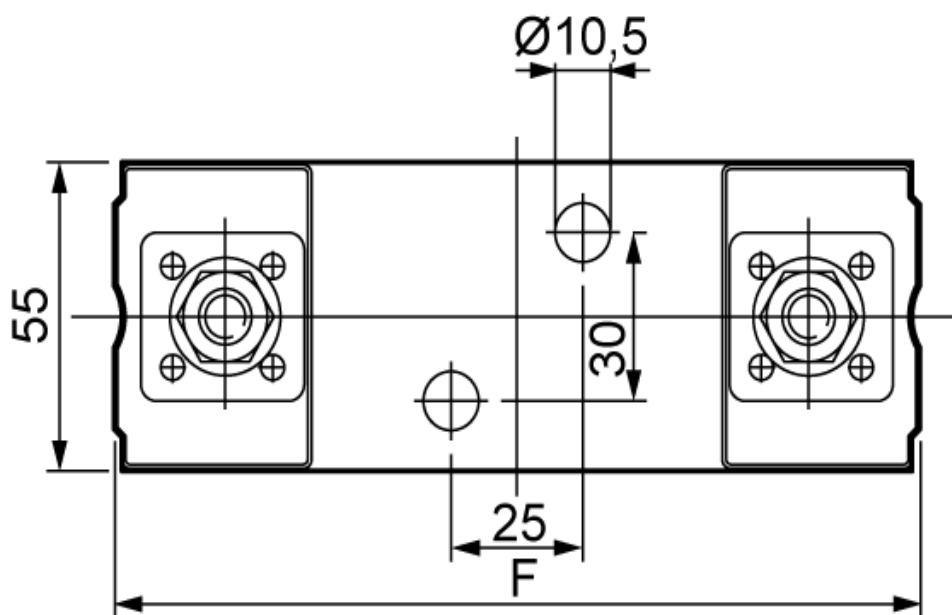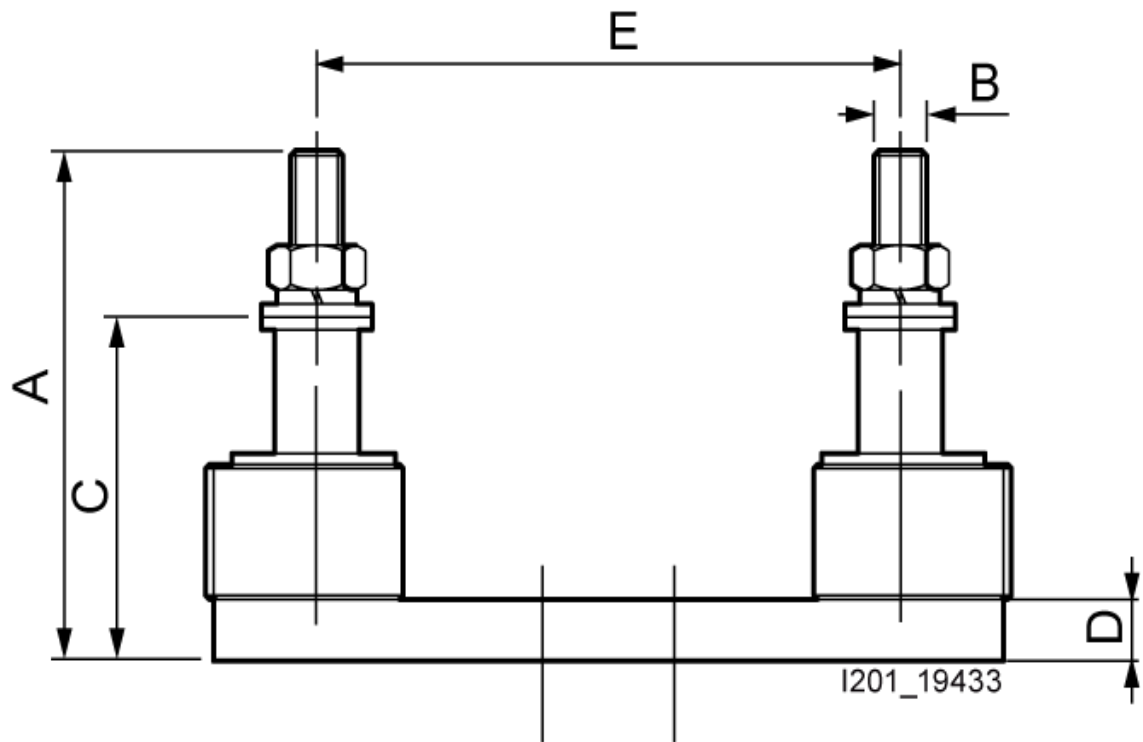

Type	Dimensions					
	A	B	C	D	E	F
3NH5463	94	M10	65	11	110	153
3NH5473	101	M10	72	11	170	211

