


Features

- ANSI MC96.1
- 0.003" (0.076mm) conductors
- Fast response, welded exposed junction
- Bare tails

RS PRO PFA Insulated ANSI Fine Gauge Exposed Junction Thermocouple (0.076mm conductors) - Type K

RS Stock No.: 0652750

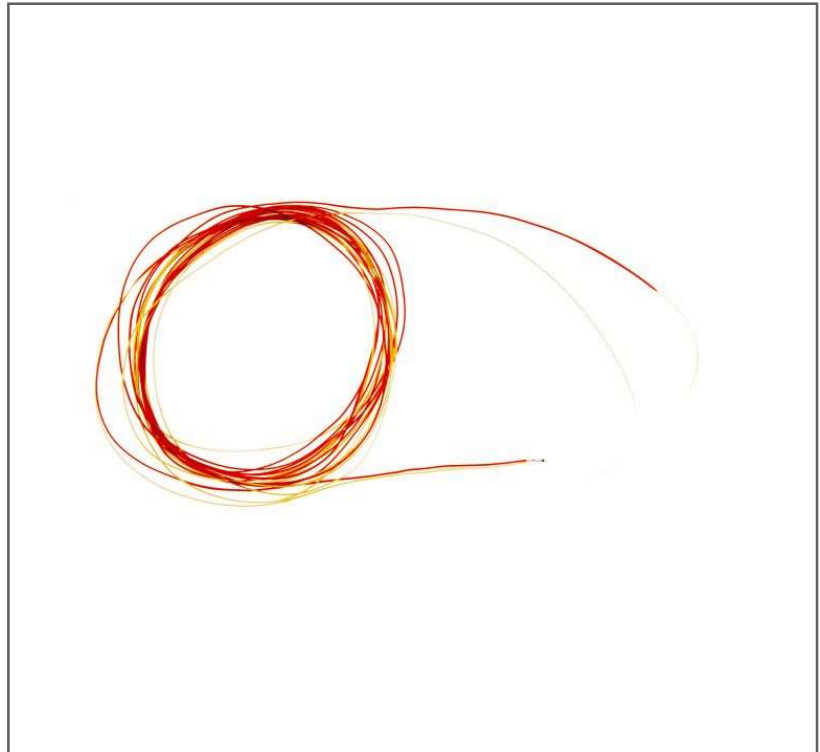

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

Exposed junction thermocouples are often used in applications where fast response times are crucial, such as in research laboratories, semiconductor manufacturing, and certain industrial processes.

General Specifications

Thermocouple Type	Type K
Temperature Measurement Range	-75°C to 260°C
Construction	Fast response, welded exposed junction
Measuring Junction	Exposed
Standards Met	ANSI
Application	Fine Gauge Exposed Welded Tip Thermocouple

Mechanical Specifications

Termination	Bare Tails
Length	0.3m (0.98ft)
Cable Insulation	0.003" (0.076mm) conductors - Teflon® PFA insulated wires

Approvals

Declarations	RoHS
--------------	------

Similar Products

RS Stock#	RS Stock#	RS Stock#	RS Stock#	RS Stock#
0.3m (0.98ft)	0.5m (1.64 ft)	1m (3.3ft)	1m (3.3ft)	2m (6.56ft)
0652750	2209491	3971589	2623210 (Pack of 10)	2209490