


## **INSTRUCTIONS FOR USE**

## **INTERMEDIATE DESIGN**

### **HYNIT™ gloves**

#### **A. Use**

These gloves are designed to protect the hands against light duty mechanical risks. They are in conformity and are marked as per requirements of the European Directive 89/686/EEC and its Amendments and they are in compliance with the European Standards EN 420 and EN 388.

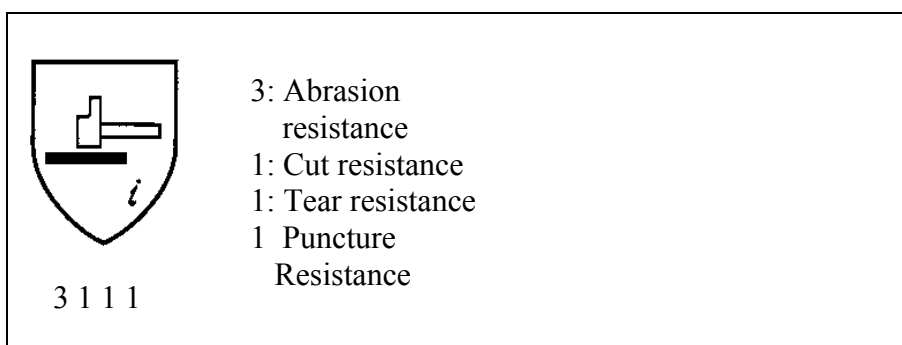

EC-Type examination certificate by ITF France ( I.D. 0072 ) – Avenue Guy De Collongue Ecully.

#### **B. Precautions for use**

NEVER USE THESE GLOVES AGAINST CHEMICALS, nor for protection against heavy duty mechanical applications.  
Do not use against flames.

Before usage, inspect the gloves for any defects or imperfections. Avoid wearing damaged or worn out gloves.

#### **C. Ingredients / Hazardous ingredients**

These gloves do not contain any ingredients which are known to be a possible cause of allergies to sensitised people.  
If allergic reactions would occur, obtain medical advice immediately.

For more information, please contact Ansell's Customer service department.

#### **D. Care instructions**

Storage : Keep out from direct sunlight; store in a cool and dry place.  
Keep out from sources of ozone or ignition.

Cleaning : The gloves can be laundered at 60 °C maximum.

#### **E. Disposal**

Used gloves may be contaminated with infectious or other hazardous materials.  
Dispose of according to Local Authority Regulations. Landfill or incinerate under controlled conditions.

Ansell Healthcare Europe  
Internationale Laan 55  
1070 Brussels  
Belgium

Type	Style	Reference	Size	Length
Regular	Sip-on	32-105*	7 , 7½ , 8 , 9 , 10	215 to 235 mm
	Safety cuff	32-800	7 , 7½, 8 , 9 , 10	260 to 295 mm
Perforated	Slip-on	32-125*	7 , 7½ , 8 , 9 , 10	215 to 235 mm
Cool	Gunn-cut	32-815	7 , 7½ , 8 , 9 , 10	240 to 260 mm

\* References 32-105 and 32-125 : Fit for special purpose