


Scheda tecnica prodotto

## LRCB 25

Supporto albero con fori filettati

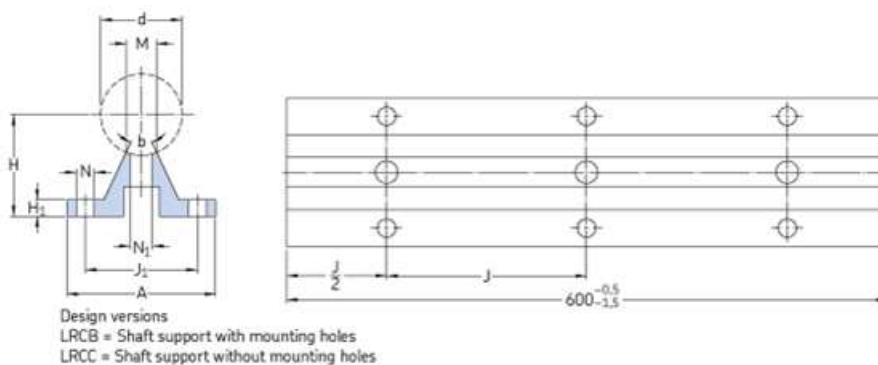

$\beta$ [°]:	50
A [mm]:	57
d [mm]:	25
H [mm]:	36
H1 [mm]:	6
J [mm]:	120
J1 [mm]:	42
L [mm]:	600
M [mm]:	10.8
N [mm]:	6.6
N1 [mm]:	9

Data: 27/05/2020

The contents of this report are the copyright of the publisher and may not be reproduced (even extracts) unless permission is granted. Every care has been taken to ensure the accuracy of the information contained in this report but no liability can be accepted for any loss or damage whether direct, indirect or consequential arising out of the use of the information contained herein.

Scheda tecnica prodotto

## LRCB 25

Supporto albero con fori filettati

Vite:	M8X25
Massa [kg]:	1.08

**Data:** 27/05/2020

The contents of this report are the copyright of the publisher and may not be reproduced (even extracts) unless permission is granted. Every care has been taken to ensure the accuracy of the information contained in this report but no liability can be accepted for any loss or damage whether direct, indirect or consequential arising out of the use of the information contained herein.