


## FEATURES

- **Polyacrylic material:** Offers excellent resistance to chemicals and high temperatures, ensuring durability.
- **Maximum operating pressure of 2000 kPa:** Suitable for high-pressure applications, providing secure sealing.
- **Maximum operating temperature of 200 °C:** Capable of withstanding high temperatures, making it versatile for various environments.
- **Rotary speed of 10 m/s:** Supports efficient operation in dynamic conditions.
- **Section size of 5 mm:** Ensures compatibility with a range of equipment sizes.

## RS PRO 8m Polyacrylic Gland Packing, 2000 kPa

RS Stock No: 606-580

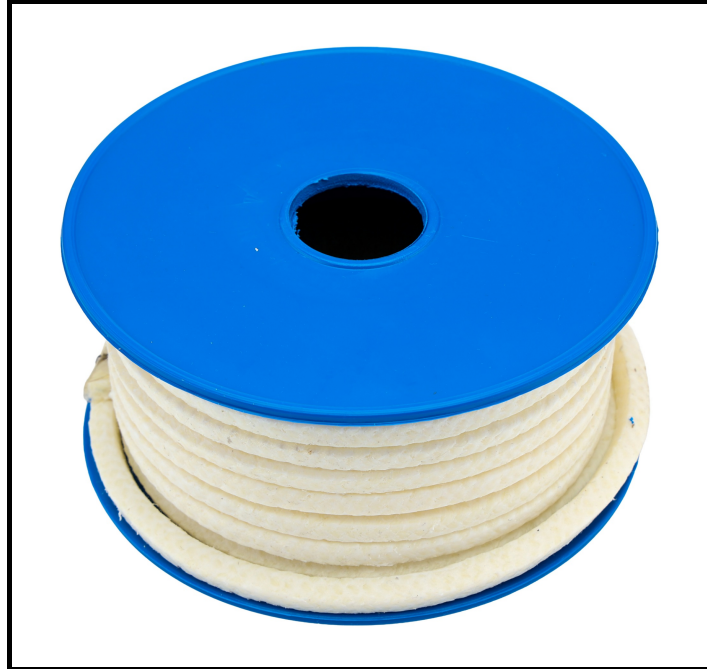

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

## Product Description

This RS PRO gland packing is designed for sealing applications in industrial environments. Made from durable polyacrylic material, it provides reliable sealing under high pressure and temperature conditions. Ideal for use in pumps and valves, it ensures minimal leakage and enhances equipment longevity.

## General Specifications

Maximum Operating Pressure	2000 kPa
Product Type	Gland & Valve Packing
Rotary Speed	10 m/s
Section	5 mm
Sub Type	Gland Packing

## Mechanical Specifications

Length	8 m
Material	Polyacrylic

## Operation Environment Specifications

Maximum Operating Temperature	200 °C
-------------------------------	--------

## Approvals

Standards/Approvals	ANSI-ESD S20.20:2021, RoHS
---------------------	----------------------------