


axial kit EAMM-A-L38-60P

Part number: 2037246

☆ Core product range

Suitable for electric drives.

FESTO

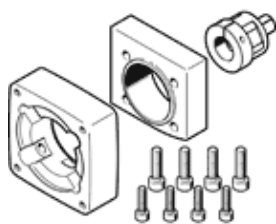

Data sheet

Feature	Value
Assembly position	Any
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	-10 ... 60 °C
Transferable torque	4.4 Nm
Product weight	300 g
Interface code, actuator	L38
Interface code, motor in	60P
Materials note	Conforms to RoHS