

Anatomical tweezers 145 mm form 40 serrated


Art.-No.	5-117
Description	Anatomical tweezers 145 mm form 40 serrated
Application	precision mechanics tweezers
Specification	with serration

Material	alloyed tool steel
Surface/Coating	polished, nickel plated
Features	abrasion resistant, stainless, stable (sturdy)
Surface resistance	/

Shape	NG: Normal tips straight
Icon No.	NG5

Dimensions and weight

A = 16 mm
B = 3 mm
Ai = /

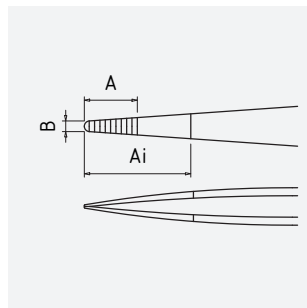

length 145 mm
weight 25 g

Application and technical data

Mechanic tweezers steel, heavy model, straight round wide with serrations.

Tool steel, corrosion protection by surface treatment