

### Specifications:

Max Current 10A

Supply Voltage 220V—250V

Terminals 4

Dimensions 85mm

Max Load 5kg

BESA Box Fixing Centres

Pre-wired for easy installation

Pre-wired cables fitted with protective covers

Compliant to BS 6973:1988 (AMD 1) and BS 5733:2010 + A1: 2013

### Stock Code



### Description

PCS7300	10Amp Plug In Ceiling Rose 3 Pin Plug Only White
PCS7310	10Amp Plug In Ceiling Rose with 3 Pin Plug
PCS7312	10Amp Plug In Ceiling Rose with 3 Pin Plug 2M PVC Flex
PCS7313	10Amp Plug In Ceiling Rose with 3 Pin Plug 3M PVC Flex
PCS7400	10Amp Plug In Ceiling Rose 4 Pin Plug Only Red
PCS7410	10Amp Plug In Ceiling Rose with 4 Pin Plug
PCS7412	10Amp Plug In Ceiling Rose with 4 Pin Plug 2M PVC Flex
PCS7413	10Amp Plug In Ceiling Rose with 4 Pin Plug 3M PVC Flex

### Warning

N.B. plugs must not be fitted on the supply side of any installation - they must be connected to the load/fitting/ appliance side of the installation. This product must be installed by a competent person in accordance with the current IET wiring regulations.

Contactum Ltd, Victoria House, 2 Blackmoor Lane, Croxley Green Business Park, Watford WD18 8GA

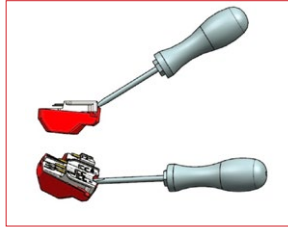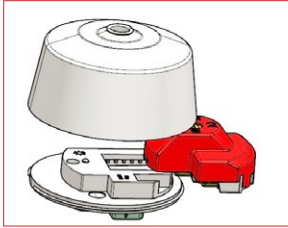

To open the plug, place a small screwdriver into the semi circular opening in the back of the plug and lever down

Inside the plug

