


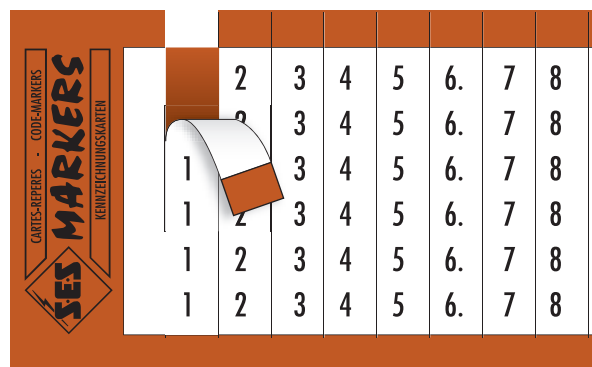

E 38

Material:	TEV vinyle covered cotton
Temperature range:	-30 to +105°C (class A) -40 to +150°C (short duration)
Operating temperature:	+10 to +40°C
Adhesive:	special thermal setting adhesive
Adherence on steel:	2,5 N/cm
Tensile strength:	80 N/cm
Dimension of the card:	255 x 48 mm
Print height:	3,1 mm
Strip number:	12 to 37 strip
Strip width:	6 to 18 mm
Strip length:	38 mm (for wires up to Ø 12 mm)
Strip thickness:	0,30 mm
Standard colours:	white - yellow
Pack:	10 cards same legend (for smaller quantities an extra charge will be applied).

Ø < 12 mm



• Product information

Figures and letters repeated	Figures and letters in series	Figures in repetitive groups

Figures and letters combined repeated	Phases repeated	Voltages repeated	Coloured cards



Article number white strip

code group	detail article	code colour	code legend
0301	0001	001	x x x x

Example for order:

E38 white strip - legend 09.

0301	0001	001	09
------	------	-----	----

Ø < 12 mm

Article number yellow strip

code group	detail article	code colour	code legend
0301	0001	004	x x x x

E38 yellow strip - legend 0 → 9.

0301	0001	004	0-9
------	------	-----	-----

legend	code legend	number strips /card	legend	code legend	number strips /card	legend	code legend	number strips /card	legend	code legend	number strips /card
0	0	37	40	40	37	80	80	37	A	A	37
1	1	37	41	41	37	81	81	37	B	B	37
2	2	37	42	42	37	82	82	37	C	C	37
3	3	37	43	43	37	83	83	37	D	D	37
4	4	37	44	44	37	84	84	37	E	E	37
5	5	37	45	45	37	85	85	37	F	F	37
6	6	37	46	46	37	86	86	37	G	G	37
7	7	37	47	47	37	87	87	37	H	H	37
8	8	37	48	48	37	88	88	37	I	I	37
9	9	37	49	49	37	89	89	37	J	J	37
10	10	37	50	50	37	90	90	33	K	K	37
11	11	37	51	51	37	91	91	37	L	L	37
12	12	37	52	52	37	92	92	37	M	M	37
13	13	37	53	53	37	93	93	37	N	N	37
14	14	37	54	54	37	94	94	37	O	O	37
15	15	37	55	55	37	95	95	37	P	P	37
16	16	37	56	56	37	96	96	37	Q	Q	37
17	17	37	57	57	37	97	97	37	R	R	37
18	18	37	58	58	37	98	98	37	S	S	37
19	19	37	59	59	37	99	99	33	T	T	37
20	20	37	60	60	33	100	100	25	U	U	37
21	21	37	61	61	37				V	V	37
22	22	37	62	62	37	00	00	33	W	W	37
23	23	37	63	63	37	01	01	33	X	X	37
24	24	37	64	64	37	02	02	33	Y	Y	37
25	25	37	65	65	37	03	03	33	Z	Z	37
26	26	37	66	66	33	04	04	33			
27	27	37	67	67	37	05	05	33	A → Z	A-Z	37
28	28	37	68	68	37	06	06	33			
29	29	37	69	69	37	07	07	33	0 → 9	0-9	37
30	30	37	70	70	37	08	08	33	0 → 10	0-10	33
31	31	37	71	71	37	09	09	33	1 → 3	1-3	36
32	32	37	72	72	37				1 → 4	1-4	36
33	33	37	73	73	37	1 → 33	\$33	33	1 → 5	1-5	35
34	34	37	74	74	37	34 → 66	\$66	33	1 → 6	1-6	36
35	35	37	75	75	37	67 → 99	\$99	33	1 → 8	1-8	32
36	36	37	76	76	37	100 → 124	\$124	25	1 → 9	1-9	36
37	37	37	77	77	37	125 → 149	\$149	25	1 → 12	1-12	36
38	38	37	78	78	37	150 → 174	\$174	25	1 → 16	1-16	32
39	39	37	79	79	37	175 → 199	\$199	25	1 → 18	1-18	36
									19 → 36	1936	36

Other legends upon request with a minimum of order of 10 cards.





Article number white strip

code group	detail article	code colour	code legend
0301	0001	001	x x x x

Article number yellow strip

code group	detail article	code colour	code legend
0301	0001	004	x x x x

Example for order:

E38 white strip - legend L1

0301	0001	001	L1
------	------	-----	----

Ø < 12 mm

E38 yellow strip - legend 1U1

0301	0001	004	1U1
------	------	-----	-----

legend	code legend	number strips /card	legend	code legend	number strips /card	legend	code legend	number strips /card	legend	code legend	number strips /card
A1	A1	33	H4	H4	33	R3	R3	33	W5	W5	33
A2	A2	33	H5	H5	33	R4	R4	33	W6	W6	33
A3	A3	33	J1	J1	33	R5	R5	33	X1	X1	33
A4	A4	33	J2	J2	33	R6	R6	33	X2	X2	33
A5	A5	33	J3	J3	33	R7	R7	33	X3	X3	33
A6	A6	33	J4	J4	33	R8	R8	33	X4	X4	33
B1	B1	33	K1	K1	33	R9	R9	33	Y1	Y1	33
B2	B2	33	K2	K2	33	R10	R10	25	Y2	Y2	33
B3	B3	33	K3	K3	33	S1	S1	33	Y3	Y3	33
B4	B4	33	K4	K4	33	S2	S2	33	Y4	Y4	33
B5	B5	33	L1	L1	33	S3	S3	33	Z1	Z1	33
C1	C1	33	L2	L2	33	S4	S4	33	Z2	Z2	33
C2	C2	33	L3	L3	33	S5	S5	33	Z3	Z3	33
C3	C3	33	L4	L4	33	S6	S6	33	Z4	Z4	33
C4	C4	33	L5	L5	33	T1	T1	33	1U	1U	33
C5	C5	33	L6	L6	33	T2	T2	33	2U	2U	33
C6	C6	33	L7	L7	33	T3	T3	33	1V	1V	33
D1	D1	33	L8	L8	33	T4	T4	33	2V	2V	33
D2	D2	33	L9	L9	33	T5	T5	33	1W	1W	33
D3	D3	33	M1	M1	33	T6	T6	33	2W	2W	33
D4	D4	33	M2	M2	33	T7	T7	33	1U1	1U1	25
D5	D5	33	M3	M3	33	T8	T8	33	1U2	1U2	25
E1	E1	33	M4	M4	33	T9	T9	33	2U1	2U1	25
E2	E2	33	M5	M5	33	T10	T10	25	2U2	2U2	25
E3	E3	33	M6	M6	33	U1	U1	33	1V1	1V1	25
E4	E4	33	O1	O1	33	U2	U2	33	1V2	1V2	25
E5	E5	33	O2	O2	33	U3	U3	33	2V1	2V1	25
F1	F1	33	O3	O3	33	U4	U4	33	2V2	2V2	25
F2	F2	33	O4	O4	33	U5	U5	33	1W1	1W1	25
F3	F3	33	O5	O5	33	U6	U6	33	1W2	1W2	25
F4	F4	33	O6	O6	33	V1	V1	33	2W1	2W1	25
F5	F5	33	O7	O7	33	V2	V2	33	2W2	2W2	25
G1	G1	33	O8	O8	33	V3	V3	33			
G2	G2	33	O9	O9	33	V4	V4	33			
G3	G3	33	P1	P1	33	V5	V5	33			
G4	G4	33	P2	P2	33	V6	V6	33			
G5	G5	33	P3	P3	33	W1	W1	33			
H1	H1	33	P4	P4	33	W2	W2	33			
H2	H2	33	R1	R1	33	W3	W3	33			
H3	H3	33	R2	R2	33	W4	W4	33			

Other legends upon request with a minimum of order of 10 cards.





Article number white strip

code group	detail article	code colour	code legend
0301	0001	001	xxxx

Article number yellow strip

code group	detail article	code colour	code legend
0301	0001	004	xxxx

Example for order:

E38 strip white - legend PHASE

0301	0001	001	PHAS
------	------	-----	------

Ø < 12 mm

E38 strip yellow - legend 230V

0301	0001	004	230V
------	------	-----	------

legend	code legend	number strips /card
PHASE	PHAS	17
PHASE-1	PHA1	12
PHASE-2	PHA2	12
PHASE-3	PHA3	12
PH	PH	33
MASSE	MASS	17
PE	PE	33
NEUT	NEUT	20
OUT	OUT	25
NEUTRE	NEUE	14
TERRE	TERR	17

legend	code legend	number strips /card
+	+	33
-	-	33
⏏	SYTE	33

legend	code legend	number strips /card
3V	3V	33
5V	5V	33
6V	6V	33
12V	12V	25
24V	24V	25
32V	32V	25
48V	48V	25
110V	110V	20
220V	220V	20
230V	230V	20
240V	240V	20
380V	380V	20

Other legends upon request with a minimum of order of 10 cards.



Code marker cards SES-MARKERS®

E 38 unprinted

Coloured strip



SES-MARKERS®

Quality TEV



E 38 unprinted

- Material:** TEV vinyle covered cotton
- Temperature range:** -30 to +105°C (class A)
-40 to +150°C (short duration)
- Operating temperature:** +10 to +40°C
- Adhesive:** special thermal setting adhesive
- Adherence on steel:** 2,5 N/cm
- Tensile strength:** 80 N/cm
- Dimension of the card:** 255 x 48 mm
- Strip number:** 33 strips
- Strip width:** 7 mm
- Strip length:** 38 mm (for wires up to Ø 12 mm)
- Strip thickness:** 0,30 mm
- Pack:** 10 cards



Article number

code group	detail article	code colour	code legend
0301	0001	xxxx	xxxx

Example for order:
E38 strip blue unprinted

0301	0001	002	BU
------	------	-----	----

code colour	001	002	003	004	005	006	007	008	010	013	015	020	021	022	088	060
code abbreviation	white	blue	green	yellow	orange	brown	red	violet	black	grey	pink	light blue	pebble gray	light green	maroon	yellow/green
	WH	BU	GN	YE	OG	BN	RD	VT	BK	GY	PK	LB	LG	LN	BX	YEGN

These marker cards are available printed upon request.



B1/10-01



B1/7-01



B2/7-02

