




Save as PDF

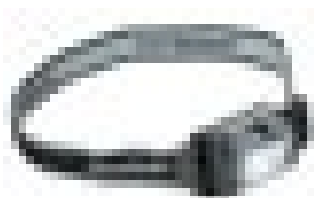

HeadsUp Lite™ 2610 LED Zone 0 Flashlight



The 2610 provides hands-free light where you need it, when you need it. A dual mode button activates all 3 LEDs for full brightness, or just 1 to extend battery life. The adjustable cloth strap fits comfortably and securely on your head, while the rubber strap grips tightly to hard hats and helmets. Both are included, as well as 3 AAA alkaline cells. The HeadsUp Lite 2610 is ideal for reading maps or light duties around the campsite as well as for work. Certified to ATEX safe for use in hazardous Zone 0 (Category 1) locations.



Black

HeadsUp Lite™ 2610 LED Zone 0 Flashlight

ANSI FL1 Specifications

LIGHT SOURCE	High	
	LED	
BATTERIES	3 AAA Alkaline (Included)	
CHARGE TIME	N/A	
VOLTAGE	4.5	
LENGTH	3.8 cm (1.49")	
WEIGHT W/ BATTERIES	0.13 kg (4.5 oz.)	
WEIGHT W/O BATTERIES	0.05 kg (1.9 oz.)	

LIGHT OUTPUT

RUNTIME (hours/min)

BEAM DISTANCE (meters)

PEAK BEAM INTENSITY (candela)

FL1 STANDARD	High	Low
	19h	
	28m	19 m.
	194cd	91cd

Materials

Body	Lens	Shroud	Switch Type
Polycarbonate	Polycarbonate	N/A	Push button On/Off switch
Clip	Contact, Spring & Retainer	O-Ring	Night Vision Film
N/A	Stainless Steel and Brass Nickel Plate	Ethylene Propylene	N/A

Configuration

Cat. #	Description
2610Z0	HeadsUp Lite™ 2610 LED Zone 0 Flashlight

HeadsUp Lite™ 2610 LED Zone 0 Flashlight Accessories

No accessories are currently available for this product

Approvals

CE Ex - II 1 G Ex ia IIC T4 Ga

Certificate: ITS09ATEX26185X