

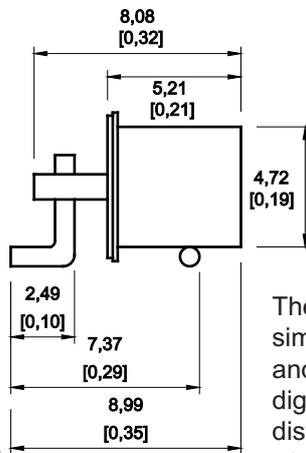


**Motion Sensor - Surface Mount**  
**Part Number : AU2401-6**  
**Product Data Sheet**


PICTURE	DIMENSIONS	CONTACT FORM
---------	------------	--------------

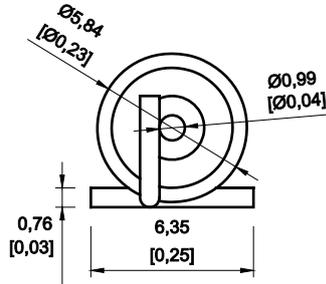

SWITCH MAYBE  
CLOSED OR OPEN IN  
ANY ORIENTATION

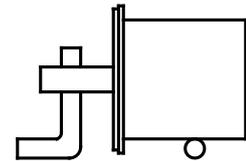

CONTACTS TRIGGERED WHEN  
DETECTING MOVEMENT OR VIBRATION

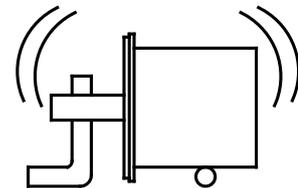

The sensor is non position sensitive offering a similar level of sensitivity whatever its position and has been designed for use with analogue or digital circuitry. The sensor reacts when disturbed by giving a fleeting change of state (ie n/o to n/c or vice versa)

**✓ RoHS Compliant**

Drawings not to scale  
All dimensions in mm nominal

### SPECIFICATION

Contact Form / Style	See above	
Switching Voltage	Max Volts DC	24
Switching Current	Max Amps	0.20
Switching Capacity	Max VA	5
Contact Resistance	Max Ohms	100@ 5V dc
Operating Temperature	Celcius	-37° - 100°
Storage Temperature	Celcius	-40° - 125°
Case Material	Steel- Gold Plated	
Mounting	Surface mount	

Applications Include	Features
----------------------	----------

- Vibration Alarm System.
- Electronic toys .
- Wake up switch.
- Consumer electronics.

- Non position sensitive
- Suitable for Alarms and non hazardous applications.
- Can be damped using a Schmitt trigger device.

Rev. No.	Revision Note	Date	Signature
2	Datasheet redesign	12-03-12	ML

As part of the company policy of continued product improvement, specifications may change without notice. Our sales office will be pleased to help you with the latest information on this product range and the details of our full design and manufacturing service. All products are supplied to our standard conditions of sale unless otherwise agreed in writing.

**Phone : (1)973 777 6900**      **www.comus-intl.com**      **Fax: (1)973 777 8405**