

CA-12S1N8A80DNX - Cable connector



1243814

<https://www.phoenixcontact.com/in/products/1243814>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



M23, Cable connector, series: CA, straight, shielded: yes, Screw locking mechanism, No. of pos. : 12, Direction of rotation: Standard, contact connection type: Socket, Crimp connection, cable diameter range: 3 mm ... 14.5 mm, coding: N, Item is lead-free in accordance with RoHS II without Exemption 6c (Pb < 0.1 %)

Your advantages

- Safe use in the field, thanks to high degree of protection
- Connector for flexible on-site assembly
- Consistent EMC protection for reliable transmission of signals
- Crimping connection: vibration- and temperature-resistant assembly

Commercial data

Item number	1243814
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	*****
Product key	ABRAEA
GTIN	4063151403911
Weight per piece (including packing)	93.2 g
Weight per piece (excluding packing)	93.2 g
Customs tariff number	85366990
Country of origin	DE

CA-12S1N8A80DNX - Cable connector



1243814

<https://www.phoenixcontact.com/in/products/1243814>

Technical data

Notes

Order information:	Order 12 x 1 mm crimp contacts separately
--------------------	---

Product properties

Product type	Circular connector (cable-side)
--------------	---------------------------------

Connector

Connection 1

Head design	Socket
-------------	--------

Insulating body

Note	Order information: Order crimp contacts Ø 1 mm separately
Coding	N
Insulation body material	PA 6.6
Connection method	Crimp connection
Contact switching type	Socket
Application	Signal
Number of positions	12
Direction of rotation	Standard
Connection profile	12
Contact diameter	1 mm
Litz wire cross-section	0.08 mm ²
Litz wire cross-section	1 mm ²
Nominal current per signal contact	8 A
Rated voltage Signal contact	48 V AC
Rated surge voltage	1.5 kV
Overvoltage category	III
Degree of pollution	3

Housing

Housing material	Turned parts: copper zinc alloy (CuZn), die-cast parts: zinc (GD-Zn)
Type of locking	Screw locking mechanism
Pg screw connection	none
Degree of protection (plugged in)	IP67
Thread type	M23

Seal

External cable diameter	3 mm ... 14.5 mm
Seal material	NBR

Environmental and real-life conditions

CA-12S1N8A80DNX - Cable connector



1243814

<https://www.phoenixcontact.com/in/products/1243814>

Ambient conditions

Ambient temperature (operation)	-40 °C ... 125 °C
Ambient temperature (storage/transport)	15 °C ... 25 °C
Permissible humidity (storage/transport)	50 % ... 65 %

CA-12S1N8A80DNX - Cable connector




1243814

<https://www.phoenixcontact.com/in/products/1243814>

Drawings

Schematic diagram

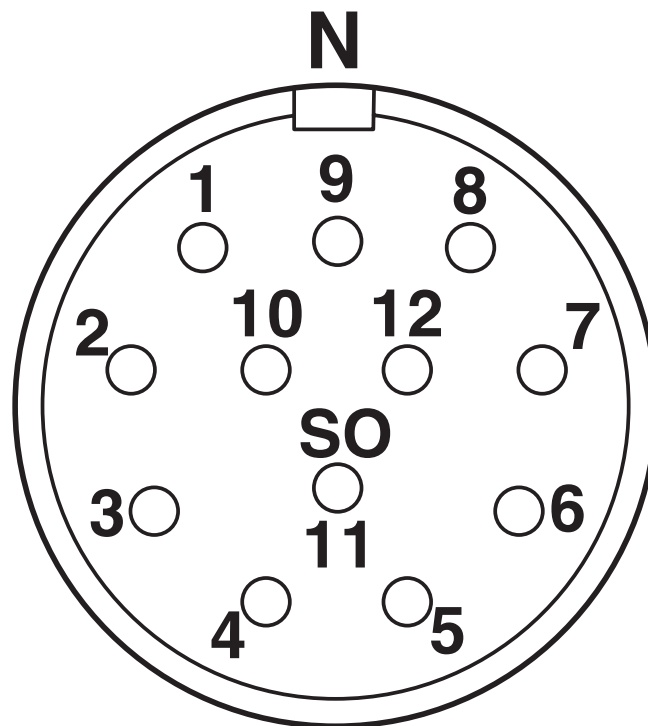

Connector pin assignment

CA-12S1N8A80DNX - Cable connector



1243814

<https://www.phoenixcontact.com/in/products/1243814>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/in/products/1243814>

cUL Recognized Approval ID: E335019-20141210				
	Nominal voltage U_N	Nominal current I_N	Cross section AWG	Cross section mm^2
	48 V	4 A	20	-

UL Recognized Approval ID: E335019-20141210				
	Nominal voltage U_N	Nominal current I_N	Cross section AWG	Cross section mm^2
	48 V	6 A	20	-

cULus Recognized				
------------------	--	--	--	--

CA-12S1N8A80DNX - Cable connector



1243814

<https://www.phoenixcontact.com/in/products/1243814>

Classifications

ECLASS

ECLASS-11.0	27440102
ECLASS-12.0	27440116
ECLASS-13.0	27440116

ETIM

ETIM 9.0	EC002635
----------	----------

UNSPSC

UNSPSC 21.0	39121100
-------------	----------

CA-12S1N8A80DNX - Cable connector



1243814

<https://www.phoenixcontact.com/in/products/1243814>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

CA-12S1N8A80DNX - Cable connector



1243814

<https://www.phoenixcontact.com/in/products/1243814>

Accessories

RC-10KS0,08-0,56 - Crimp contact

1241093

<https://www.phoenixcontact.com/in/products/1241093>



Crimp contact, Socket, turned, Single contact, contact diameter: 1 mm, crimp range: 0.08 mm² ... 0.56 mm², Contact release tool not necessary for the 12- and 17-pos. crimp versions of the M23-PRO series, Item is lead-free in accordance with RoHS II without Exemption 6c (Pb < 0.1 %)

RC-10KS0,75-1,00 - Crimp contact

1241572

<https://www.phoenixcontact.com/in/products/1241572>



Crimp contact, Socket, turned, contact diameter: 1 mm, crimp range: 0.75 mm² .. 1 mm², Contact release tool not necessary for the 12- and 17-pos. crimp versions of the M23-PRO series, Item is lead-free in accordance with RoHS II without Exemption 6c (Pb < 0.1 %)

CA-12S1N8A80DNX - Cable connector

1243814

<https://www.phoenixcontact.com/in/products/1243814>



CA-Z0077X - Metal protective cap

1245447

<https://www.phoenixcontact.com/in/products/1245447>



Metal protective cap, Item is lead-free in accordance with RoHS II without Exemption 6c (Pb < 0.1 %)

SF-Z0028 - Torque screwdriver

1607456

<https://www.phoenixcontact.com/in/products/1607456>



Torque screwdriver, series: RC, UC, SH, SF

CA-12S1N8A80DNX - Cable connector

1243814

<https://www.phoenixcontact.com/in/products/1243814>



SF-Z0027 - Hook wrench

1607455

<https://www.phoenixcontact.com/in/products/1607455>



Hook wrench, series: RC, UC, RF, SF

RF-Z0014 - Color coding

1620588

<https://www.phoenixcontact.com/in/products/1620588>



Color coding, color: green

CA-12S1N8A80DNX - Cable connector



1243814


<https://www.phoenixcontact.com/in/products/1243814>

RF-Z0015 - Color coding

1620592

<https://www.phoenixcontact.com/in/products/1620592>

Color coding, color: orange

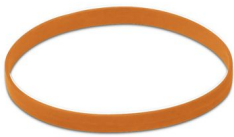

RF-Z0016 - Color coding

1620593

<https://www.phoenixcontact.com/in/products/1620593>

Color coding, color: black



CA-12S1N8A80DNX - Cable connector

1243814

<https://www.phoenixcontact.com/in/products/1243814>



RF-Z0003X - Square mounting flange

1242369

<https://www.phoenixcontact.com/in/products/1242369>



Square mounting flange, Axial seal, 4xM3, flange dimensions: 35 mm x 35 mm, series: RF, Item is lead-free in accordance with RoHS II without Exemption 6c (Pb < 0.1 %)

RC-22S2000 - Crimp contact

1603327

<https://www.phoenixcontact.com/in/products/1603327>



Crimp contact, Socket, rolled, Single contact, contact diameter: 1 mm, crimp range: 0.22 mm² ... 0.56 mm², Single contact, Item is lead-free in accordance with RoHS II without Exemption 6c (Pb < 0.1 %)

CA-12S1N8A80DNX - Cable connector



1243814

<https://www.phoenixcontact.com/in/products/1243814>

RC-22S2300 - Crimp contact

1603330

<https://www.phoenixcontact.com/in/products/1603330>



Crimp contact, Socket, rolled, Taped product, number of pieces per reel: 500, contact diameter: 1 mm, crimp range: 0.22 mm² ... 0.56 mm², Item is lead-free in accordance with RoHS II without Exemption 6c (Pb < 0.1 %)

RC-22S2400 - Crimp contact

1603332

<https://www.phoenixcontact.com/in/products/1603332>



Crimp contact, Socket, rolled, Taped product, number of pieces per reel: 10000, contact diameter: 1 mm, crimp range: 0.22 mm² ... 0.56 mm², Item is lead-free in accordance with RoHS II without Exemption 6c (Pb < 0.1 %)

CA-12S1N8A80DNX - Cable connector

1243814

<https://www.phoenixcontact.com/in/products/1243814>



PROT-M23-SG-IT-IP20 - Plastic protective cap

1577206

<https://www.phoenixcontact.com/in/products/1577206>

Plastic protective cap, M23, series: CA, RC, RF, UC, RM



Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.

A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420

info@phoenixcontact.co.in