




Blocks & Holders

Miniature Fuses

Clips

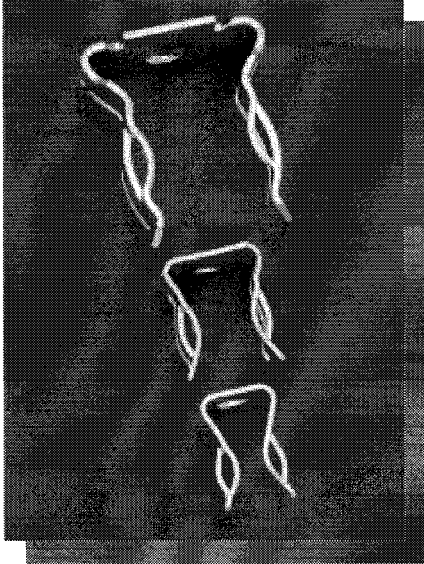

30A & 60A FERRULE - FUSE CLIPS

Fuse Clips for 30 & 60 Ampere Ferrule-type Fuses

CAT. NUM.	REF. NUM.	FIG.	FOR FUSE RATING/SIZE:		MOUNTING DETAILS	
			AMPS (max.)	FERRULE DIA.	HOLE SIZE	SCREW SIZE
C08915P	R215479	1	30	13/32"	.172" dia.	#8
C08919P	P217524	2	30	13/32"	.196" dia.	#10
C08916P	V215988	3	30	9/16"	.172" dia.	#8
C08917P	R216491	4	30 or 60	13/16"	.22" x .30"	#10
C08918P	F217010	5	60	1-1/16"	.22" x .30"	#10

All clips are UL Recognized: Guide IZLT2, File C52203

All clips are tin-plated copper alloy, non-spring reinforced.

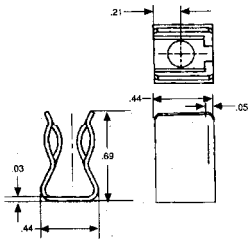


FIGURE 1

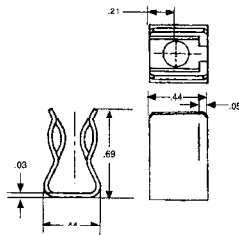


FIGURE 2

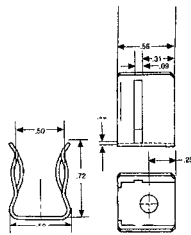


FIGURE 3

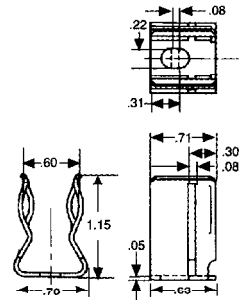


FIGURE 4



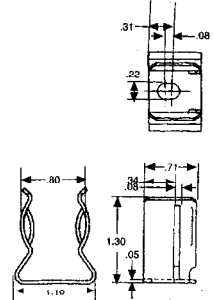


FIGURE 5

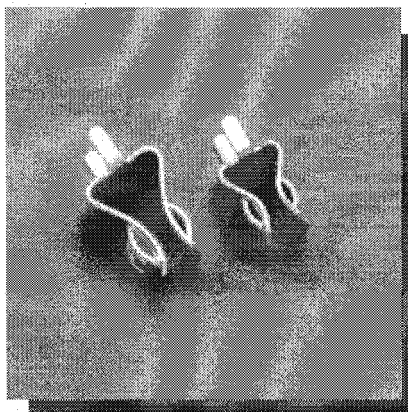


SDC6 PC BOARD CLIPS

- ✓ PC board mount fuse clip
- ✓ For 1/4" diameter fuses
- ✓ Tin plated hard brass

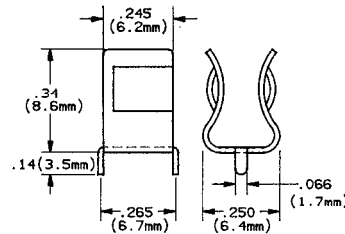

SDC5 PC BOARD CLIPS

- ✓ PC board mount fuse clip
- ✓ For 5mm diameter fuses
- ✓ Tin plated hard brass

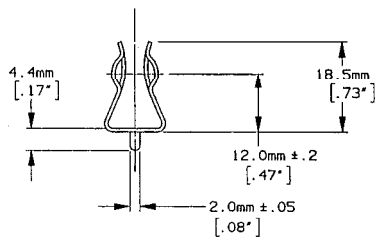

SDC7 PC BOARD CLIPS

- ✓ PC board mount fuse clip
- ✓ For 13/32" (10mm) diameter fuses
- ✓ Tin plated spring brass

