


**HIGH RESISTANCE CEILING LIGHT**  
**GIADA**

GIADA153S  
16,0 W - 1700lm - 4000K

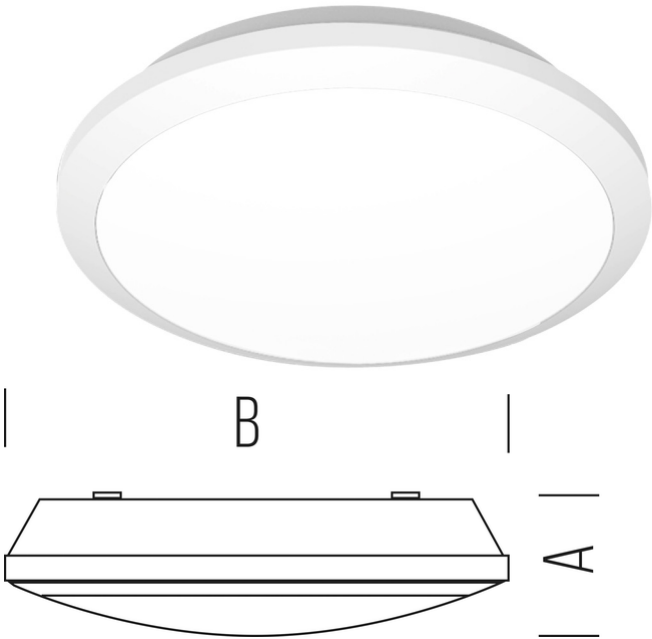

| DIMENSIONS |  |
|------------|--|
| 1          |  |

| GENERAL INFORMATIONS        |                                        |
|-----------------------------|----------------------------------------|
| Code                        | GIADA153S                              |
| Ean                         | 8031453023669                          |
| Family                      | HIGH RESISTANCE<br>CEILING LIGHT GIADA |
| Technology                  | LED                                    |
| Body material               | PC                                     |
| Diffuser / lens material    | PC                                     |
| Operating temperature (° C) | -20 - +40                              |

| PACKAGING |     |
|-----------|-----|
| Packaging | BOX |
| Pack      | 5   |

| ACCESSORIES                                                                       |                   |          |
|-----------------------------------------------------------------------------------|-------------------|----------|
|   | GIADA ACCESSORIES | GIADAT0B |
|   | GIADA ACCESSORIES | GIADAT1B |
|   | GIADA ACCESSORIES | GIADAT1W |
|   | GIADA ACCESSORIES | GIADAT2B |
|  | GIADA ACCESSORIES | GIADAT2W |

| LIGHTING DATA                |           |
|------------------------------|-----------|
| Kelvin (°)                   | 4000      |
| Lumen                        | 1700      |
| Beam (°)                     | 120       |
| Luminous efficacy (lm / W)   | 106,25    |
| Color rendering (CRI)        | >80       |
| TECHNICAL FEATURES           |           |
| Power (W)                    | 16,0      |
| Supply voltage (V) / Max (V) | 220 / 240 |
| Power frequency (Hz)         | 50/60     |
| Insulation class             | 2         |
| Power factor                 | >0,9      |
| Dimmer compatibility         | NO        |

## HIGH RESISTANCE CEILING LIGHT GIADA

GIADA153S

16,0W - 1700lm - 4000K

- IK10 high resistance polycarbonate ceiling light
- High efficiency up to 115 lm/W
- Flicker-Free
- Lockable ring with vandal-proof Allen key, screen fixed with screws (not visible)
- Double input hole for in / out connection
- Predisposition for through connection on the sides
- Also available with 3h lasting emergency module at 150 lm
- Also available with microwave sensor programmable by dip-switch (sensitivity, ambient light level, duration)

Predisposto per terminali IP65  
optional (non inclusi)

IP65 connection terminal is  
optional (not included)



Fori posteriori per  
inserimento cavo loop in /  
loop out compatibile con  
connessioni da 68/78mm

Holes at the back side  
of housing for loop in/  
loop out. Compatible with  
68/78mm junction box

